

Magnetic stop for aluminium profiles

Shuts using magnetism

ACLAPA

- Rapid closing mechanism for doors
- Material

Black glass fibre reinforced nylon
Retaining force : 30-50N approx

Advantages



- Suitable for PRF aluminium profiles

Info

- No mounting screws supplied (see PRF-ECL-M6 and BHC6)
- Not sold individually, contact us for details



Typical application

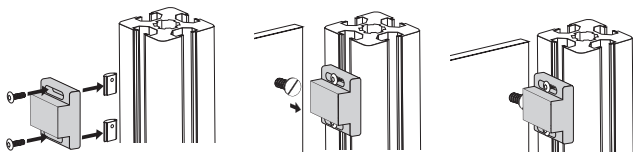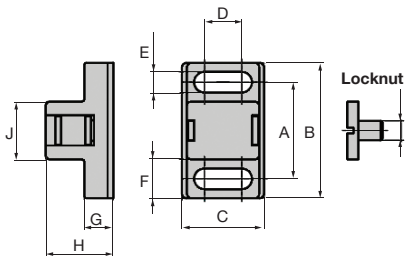

INCREASED STOCK

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	DIN921 locknut	A	B	C	D	E	F	G	H	J	Weight (g)	Stock*	Price each 1 to 49
ACL-APA-20	M4x5	20	28	17	7,7	4,3	8	6	14	12	9	✓	3,83 €
ACL-APA-30	M5x6	30	40	28	13,5	6,3	10,5	10	20	18,4	39	✓	5,09 €

* Depending on availability - Dimensions in mm

Our other products



PF20

Worm and wheel gear reducer, up to 5 Nm



SBRtool

Chain tool, Drive chain maintenance tools



HTD5M_09

HTD Heavy duty timing pulley, HTD5 Aluminium



RDCss

Rigging screw with 2 jaws stainless steel, Stainless steel



DB_ECO

Eco. range steel bevel gear, 2:1



 
GMC_GMK_BR

Guiding profile clamp, Flat or rounded



PGB

Accessory-holder for aluminium profile, Tool holder



PRF_PSA

Shaft support for aluminium profile, Shaft support



SUP

Self-centering clamping hub steel, Without locknut



FTSN

Supported shaft for linear guide, Steel shaft / Aluminium



M0

Worm and wheel set, Non hardened steel



DER63

Stainless steel AC asynchronous motor 0.18 kW, 0.18kW

Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm



PRF_ECL

Nut for aluminium profile, Steel square nut with tab



ACL-APB

Closing system for aluminium profile, Magnetic door stop