

Floor anchor for aluminium profiles



ACLEFS



Right angled floor anchor

- For securing aluminium profiles to a floor

- Material :
Zamak

Advantages

- Suitable for use with PRF aluminium profiles
- Only for use with profiles wider than 40mm

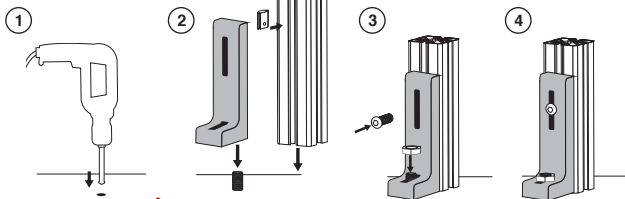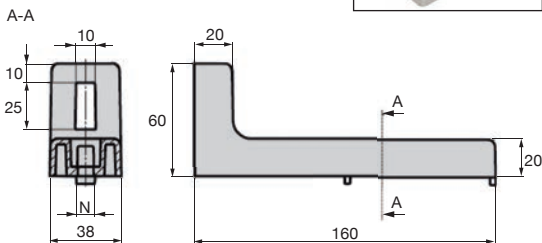

INCREASED STOCK

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	N	Weight (g)	Stock*	Price each 1 to 49
ACL-EFS-160	8	110	✓	11,36 €

Dimensions in mm



Floor anchor for aluminium profiles

Adjustable height floor anchor **ACLEFS/A**



- For securing aluminium profiles to a floor

Material:
Zamak

Advantages

- Adjustable
- Suitable for use with PRF aluminium profiles

Adjustable

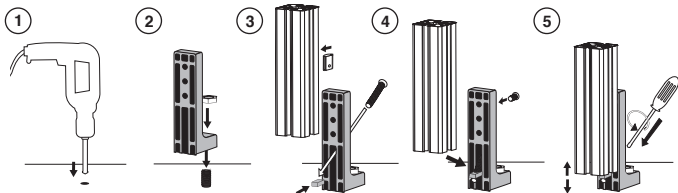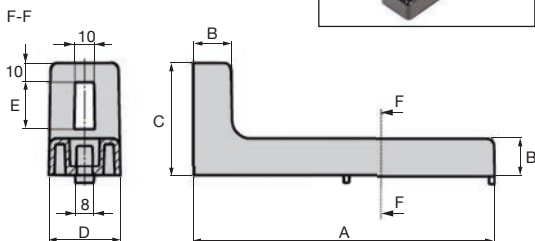

INCREASED STOCK

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Profile size (mm)	A	B	C	D	E	Max height	Masse (g)	Stock*	Price each 1 to 49
ACL-EFS-120/A	30 mini	120	15	45	28	19	52	88	✓	12,72 €
ACL-EFS-160/A	40 mini	160	20	60	38	29	72	120	✓	17,58 €

Dimensions in mm

Our other products



ZDB

Machined plastic
bevel gear , 2:1



FRtool

Tool for thread repair
inserts, Assembly tool



CHAupa

Front hinge, 270°



BAC105

Storage bin, 8mm



ACM_AZ

Mounting bracket for
bonnet fastener, Hook



BH01

Single housed
bearing, Bearing fitted
with adhesive



SVR5

Screwjack with
travelling nut, with
moving nut



SSHBR4

Stainless steel bevel
gear, 1,5:1 2:1 3:1



CLG1

Moulded plastic spur
gear, Moulded plastic
(nylon)




BAC105

Storage bin, 8mm



AT10-BAR

AT type tooth bar
stock, AT10

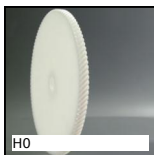

H0

Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)

Complementary products



PRF4545

Standard aluminium
profile, 45 x 45 mm