



Roller block for aluminium profiles

Create your own roller track

ACLERP

- Roller block for PRF aluminium profiles
- Materials
 - Black glass fibre reinforced nylon
 - Rollers : POM
- Exists in 2 versions, with and without guide
- Max load : 100N each

Advantages




- Click to install



ACL-ERP-SG



ACL-ERP-AG

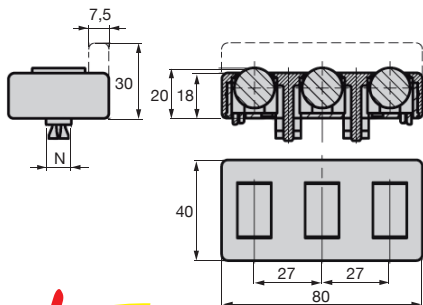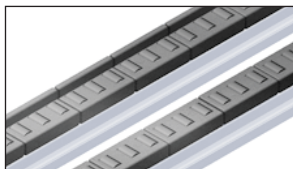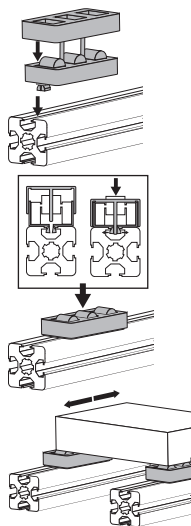

INCREASED STOCK


DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request


Part number	Version	N	Weight (g)	Stock*	Price each 1 to 49
ACL-ERP-SG	Without guide rail	8-10	43	✓	4,10 €
ACL-ERP-AG	With guide rail	8-10	48	✓	4,64 €

* Depending on availability - Dimensions in mm

Our other products

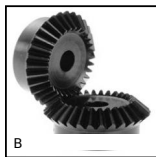

B
Steel bevel gear, 1:1

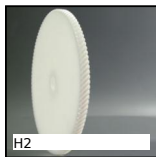

H2
Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)



SLB

Indexing plunger,
steel class 5.8



METEB

Self-lubricating
blanks, Bronze BP25



INS

Self tapping steel
insert, Steel



FR

Steel thread inserts,
Steel



SEV

Vertical stirrup toggle
clamp, Vertical Latch
Clamp - stainless steel



 
AKN

Bellows coupling
Gerwah®, from 22 to
180Nm



BMF

Knurled knob -
female, Knurled -



TBL

Mini leadscrew table
with metric thread,



CHA35

Hinge for aluminium
profile, Hinge



KH

Linear bearing, Light

Complementary products



PRF4545

Standard aluminium
profile, 45 x 45 mm