



# Latch for aluminium profiles

## Spring operated latch

## ACLLPP

### - Spring operated latch for aluminium profiles

#### - Material

Body : Zamak

Handle : Black nylon

Nut : Stainless steel


### Advantages

- Suitable for PRF aluminium profiles




- Mounts in any position

### Info

- No mounting screws supplied (see PRF-ECL-M6 and BHC6)

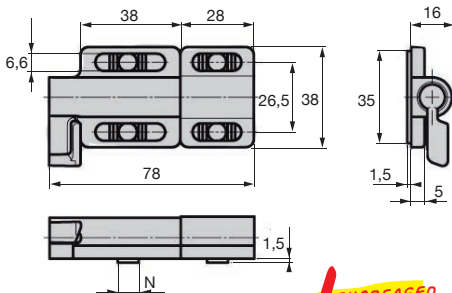

**INCREASED STOCK**

 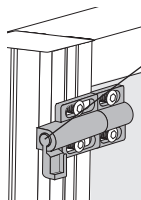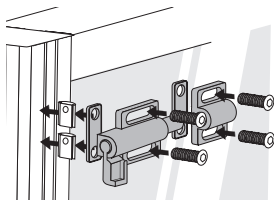

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number | N    | Weight (g) | Stock* | Price each 1 to 49 |
|-------------|------|------------|--------|--------------------|
| ACL-LPP-78  | 8-10 | 120        | ✓      | 16,46 €            |

\* Depending on availability - Dimensions in mm

## Our other products



BH01  
Single housed bearing, Bearing fitted with adhesive



ZBconique  
Machined plastic bevel gear, 1:1



WTM  
Tightening washer - DIN6340, Steel



GE32  
Sprung toggle latch with connecting link, Standard



DB  
Steel bevel gear, 2:1




HG8-ECO  
Eco range Spur gear, Steel C45



PTA40  
Articulated foot with solid base foot Ø 40, 30000N



 PSP  
Support profile, Panel support



RDE-W  
Sealing washer Hygienic Usit®, Stainless steel - White



VRC1  
Retaining clamp, single sided, Single sided



ACLALF  
Adjustable foot for aluminium profile, Ideal for workstations



AT10-25ECO  
AT type timing pulley, Economy range - AT10 aluminium

## Complementary products



PRF4545  
Standard aluminium profile, 45 x 45 mm



PRF\_ECL  
Nut for aluminium profile, Steel square nut with tab