



Latch for aluminium profiles

Spring operated latch

ACLLPP

- Spring operated latch for aluminium profiles

- Material

Body : Zamak

Handle : Black nylon

Nut : Stainless steel


Advantages

- Suitable for PRF aluminium profiles




- Mounts in any position

Info

- No mounting screws supplied (see PRF-ECL-M6 and BHC6)

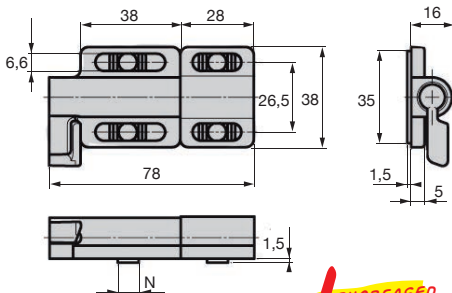

INCREASED STOCK

 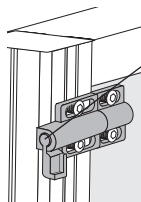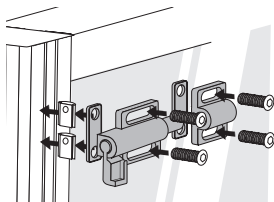

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	N	Weight (g)	Stock*	Price each 1 to 49
ACL-LPP-78	8-10	120	✓	16,46 €

* Depending on availability - Dimensions in mm

Our other products



PGNT

Thermoplastic T handle, With threaded spindle



WINGbrEcrou

Manually tightened wing nut DIN315, Brass DIN 315



PRF3232

Standard aluminium profile, 32 x 32 mm



BFM

Flanged bronze nut, Bronze - 1 thread



VQTplqn

Quarter-turn clamp lock - Clamping plate, Flush mounting



CDC

Conical compression spring, Conical



PP35

Worm and wheel gear reducer, from 2.20 to 4.10 Nm



PRF_BV

Screw block, Panel addition and fastening



PRF_FIX_STD

Fastener for aluminium profile, Standard fastener



MRS

Stainless steel metric section rack, Stainless steel



BOX-NINA

Self locking nut - DIN985, Box set of steel nuts



HTD8M_50

HTD Heavy duty timing pulley, HTD8 Cast

Complementary products



PRF4545

Standard aluminium profile, 45 x 45 mm



PRF_ECL_

Nut for aluminium profile, Steel square nut with tab