

Hook for bonnet fastener

Stock







ACM-AZ ACM-BZ

Easy fastening

- Material : Plated steel
- For use with the ACM-TRI-120 bonnet fastener

Info.

- Not sold individually, please contact us for details

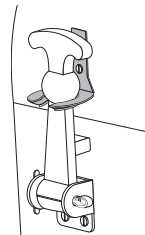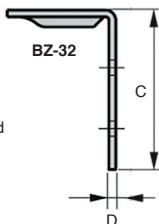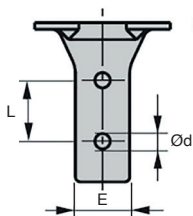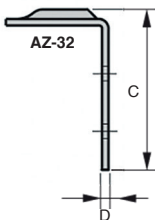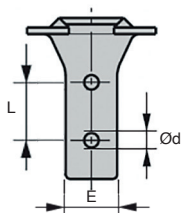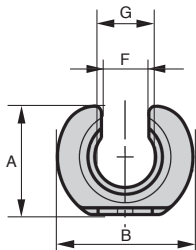

DISCOUNTS

Qty	1+	51+	101+	250+
Disc.	List	-10%	-15%	On request

Part number	A	B	C	D	E	Ød	F	G	L	Stock*	Price each
											1 to 50
ACM-AZ-32	32	40	50	2	16	4	15	18	18	✓	2,26 €
ACM-BZ-32	32	38	44	2	16	4	15	18	18	✓	2,26 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tel. +33(0)4 37 496 496

Our other products



BHEX

Hexagonal cap, Black technopolymer



HLC24

Right angle spiro bevel gearbox, Up to 78Nm



BLHB60

Right angled gearbox, bored shafts, up to 70 Nm



BOX-CSss

Hose clamp, Box set of stainless steel hose clamps



SBF

Sealed flange bearing unit for Food Industry, cover



YG1

HEAVY DUTY spur gear, Steel 35NCD6



RTE

Rotex®, jaw coupling, Aluminium



BOX-TOR-ORFS

Box set of Nitrile O-rings NBR90Sh A, 7.65 x 1.78mm to 37.82 x 1.78



PX

Optional output shaft stainless steel, P



PV1R

Adjustable suction-cup support, Standard



WSSss

Symmetrical S shaped hook stainless steel,



M1

Worm and wheel set, Non hardened steel

Complementary products



ACM_TRI

Manual bonnet fastener, Black rubber fastener



ACM_DZ

Clip for bonnet fastener, Clip