


- **Material** : Plated steel
- Used to mount the **ACM-TRI-120** bonnet fastener

Info.

- **Not sold individually**, please contact us for details

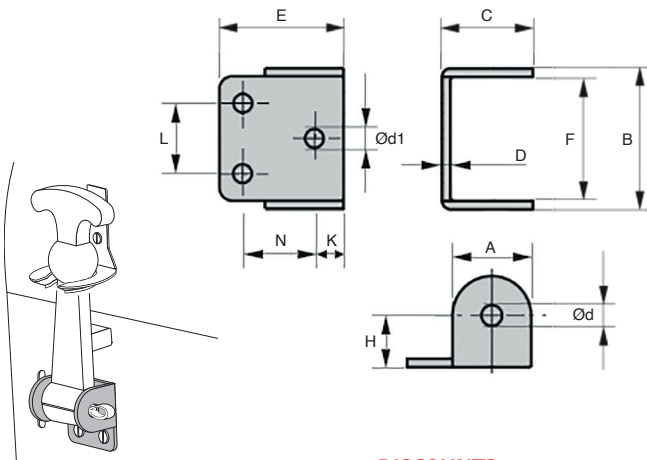

Typical application

DISCOUNTS

Qty	1+	51+	101+	250+
Disc. List	-10%	-15%	On request	

Part number	A	B	C	D	E	F	Ød	Ød1	H	L	N	K	Stock*	Price each 1 to 50
ACM-DZ-23	19	34	22	2	30	30	5	4	12	18	15	7	✓	2,47 €

*Depending on availability - Dimensions in mm

Our other products



PTA50

Articulated levelling foot, pressed base Ø50, Ø 50



PSG1HC

Skive hobbled spur gears - precision range, Case hardened steel 20NCD2



INS150

Self tapping insert with collar-coarse thread, With collar-coarse t...



PITAss

Locking bolt, with T handle



PP60

Worm and wheel gear reducer, from 17.80 to 34 Nm



RPCtc

Swivel castor with central hole, Steel - Polyamide



KKSS

Rounded end feather key, Stainless steel



GB-RA

Brass spur gear, Brass CuZn39Pb3



T39_T49

Extension spring in metre length steel, by the metre



PR65C

Half-articulated foot Ø 65, Ø 65



PRF_ROUL

Castor for aluminium profile, No brake



LRR-53

Spring loaded latch, Spring return latch - stainless steel

Complementary products



ACM_TRI

Manual bonnet fastener, Black rubber fastener



ACM_AZ

Mounting bracket for bonnet fastener, Hook