


- **Material** : Plated steel
- Used to mount the **ACM-TRI-120** bonnet fastener

Info.

- **Not sold individually**, please contact us for details

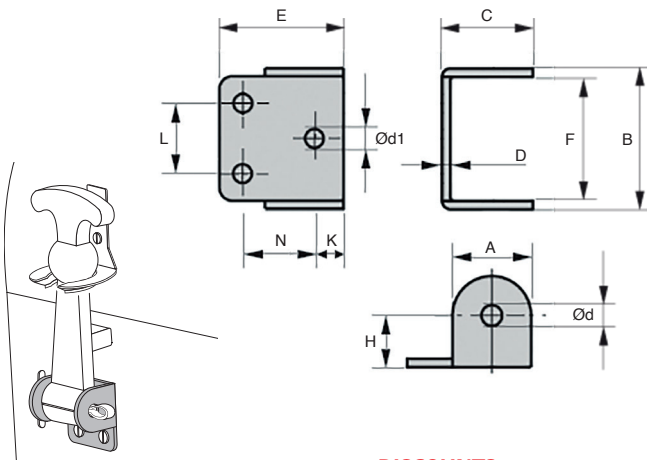

Typical application

DISCOUNTS

Qty	1+	51+	101+	250+
Disc. List	-10%	-15%	On request	

Part number	A	B	C	D	E	F	Ød	Ød1	H	L	N	K	Stock*	Price each
ACM-DZ-23	19	34	22	2	30	30	5	4	12	18	15	7	✓	1 to 50 2,47 €

*Depending on availability - Dimensions in mm

Our other products



PSG1

Spur gear - precision range, Case hardened steel 20NCD2



PCS_PA6

Plastic sprocket, 12.7mm (DIN 08B-1)



BCA

Steel splined collar, Steel



PRF_CH

Cable-carrier chain for aluminium profile, Supplied in metre lengths



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane



M0

Worm and wheel set, Unhardened steel



HBM

Adjustment bushing for half-rail guide, Adjustment bushing



BTC20_10

End cap for rectangular tube, Standard



BGC

Oldham coupling, Clamp



E20

Right angle helical reducers, from 0.60 to 3.84 Nm



COA-COG

Surface mounting plate, Surface mounting plate for ball joint



MFBC

Flexible Bellows coupling, Aluminium and Bronze - with clamping jaw

Complementary products



ACM_TRI

Manual bonnet fastener, Black rubber fastener



ACM_AZ

Mounting bracket for bonnet fastener, Hook