


- **Material** : Plated steel
- Used to mount the **ACM-TRI-120** bonnet fastener

Info.

- **Not sold individually**, please contact us for details

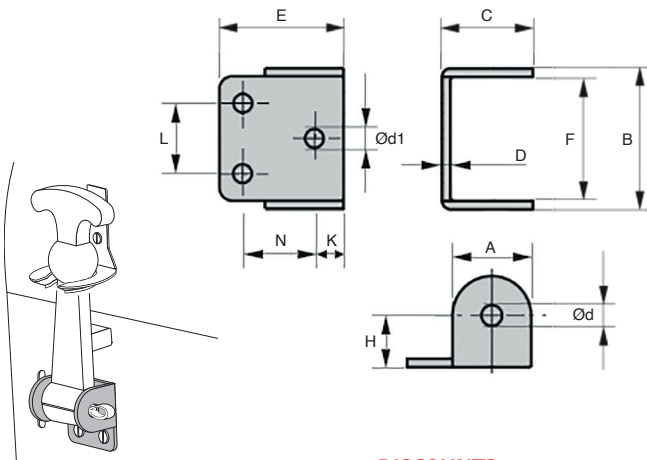

Typical application

DISCOUNTS

Qty	1+	51+	101+	250+
Disc.	List	-10%	-15%	On request

Part number	A	B	C	D	E	F	Ød	Ød1	H	L	N	K	Stock*	Price each
ACM-DZ-23	19	34	22	2	30	30	5	4	12	18	15	7	✓	1 to 50 2,47 €

*Depending on availability - Dimensions in mm

Our other products



GPB5S

Threaded spherical knob, Stainless steel 304



G-ECO

Eco range Spur gear, Steel C45



TUBE25_25

Square Tube, Aluminium or Stainless steel



SH3

Parallel axis helical gear, Steel 20NCD2




FDS

Flexible drive shaft, Masterflex® Steel, with PVC casing



SSG1

 Stainless steel spur gear, Stainless steel 304L



M1

Worm and wheel set, Bronze



RBGpl

Fixed castor with plate, Steel - grey rubber



PW_PWG3

Worm - precision range, Steel



VDSQ

Sliding lock adjustment system, Sliding lock for square profile



CHAuss

Screwed hinge, 270°



MSP23

Masterplate® glueable insert Ø23, Cylindrical Ø23 with tapped ins...

Complementary products



ACM_TRI

Manual bonnet fastener, Black rubber fastener



ACM_AZ

Mounting bracket for bonnet fastener, Hook