

- Manually fastened using a hook
- Split pin supplied
- Material :  
Black rubber, Shore 65/70

### Advantage



- Very easy to use

### Info.

- Not sold individually, please contact us for details

### Accessories

- See ACM-AZ-32 and ACM-BZ-32 hooks and ACM-BZ-23 bracket (t.imagetome1 p.156, t.imagetome1 p.157)

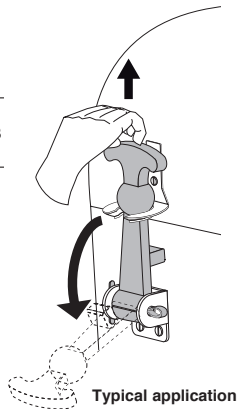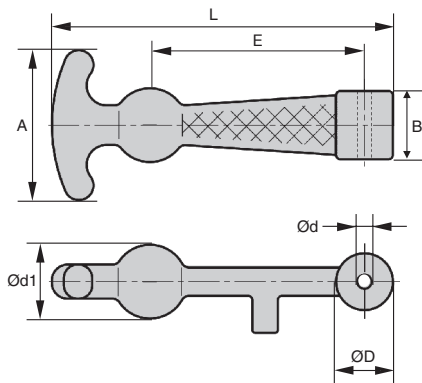

### DISCOUNTS

Qty	1+	51+	101+	250+
Disc.	List	-10%	-15%	On request

Part number	E			A	B	ØD	Ød1	Ød	Stock*	Price each 1 to 50
	L	At rest	Under tension							
ACM-TRI-120	120	74	77 <sup>+2</sup>	54	25	19	25	4	✓	4,10 €

\*Depending on availability - Dimensions in mm

## Our other products



RJUM05  
Drylin R® linear bearing housing, Closed - Long



UTKswrr  
V shaped channel UtiliTrak®, V rail



GMK17\_RG  
Joint for guiding profile, Rounded



BABTss  
303 Stainless steel ball pin, 303 Stainless steel



RIMple  
Locking castor, with mounting plate



PRF\_GAL  
Roller for aluminium profile, Fixing kit for roller eccentric



TIF  
Threaded rod - DIN975, Stainless steel A2



SBS\_L  
Chain link, Stainless steel



BPQ  
Quadro linear ball bearing unit, Included 4 linear ball bearings



HLA19  
Right angle spiro bevel gearbox, Up to 43Nm



PLM-SC  
Magnetic stud with threaded hole, With threaded hole



PTRSS  
Idler chain sprocket, For hostile environments

## Complementary products



ACM\_AZ  
Mounting bracket for bonnet fastener, Hook



ACM\_DZ  
Clip for bonnet fastener, Clip



GEC  
Rubber latch clamp with strike plate, Lockable