

- Manually fastened using a hook
- Split pin supplied
- Material :
Black rubber, Shore 65/70

Advantage

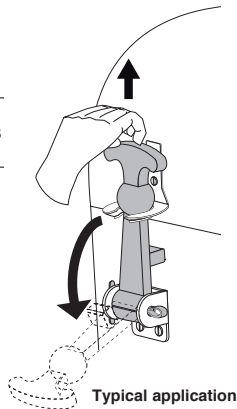
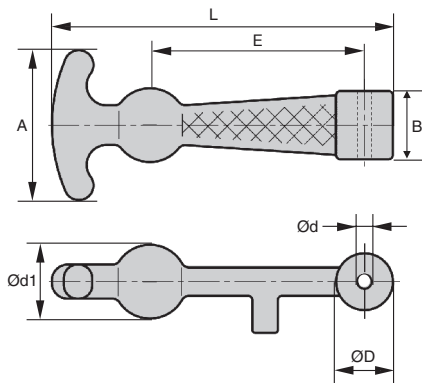
- Very easy to use

Info.

- Not sold individually, please contact us for details

Accessories

- See ACM-AZ-32 and ACM-BZ-32 hooks and ACM-BZ-23 bracket (t.imagetome1 p.156, t.imagetome1 p.157)

**DISCOUNTS**

Qty	1+	51+	101+	250+
Disc.	List	-10%	-15%	On request

Part number	E			A	B	ØD	Ød1	Ød	Stock*	Price each 1 to 50
	L	At rest	Under tension							
ACM-TRI-120	120	74	77 ⁺²	54	25	19	25	4	✓	4,10 €

*Depending on availability - Dimensions in mm

Our other products



IN2

Internal gear, Steel
20NCD2



ECF

Well nut, Chloroprene
elastomer



BOX-TOR-H

Box set of Nitrile O-
rings in nitrile, 3.00 x
2.00mm to 45.20 x
4.00



PENV

Recessed handle,
screw fixing



PF60

Worm and wheel gear
reducer, up to 118
Nm



AC144

Strike for toggle latch,
22mm



SFWR

End support, Surface
mounting



 
DIA

Ring operated locking
bolt, with ring



CDC

Conical compression
spring, Conical



RPP5

RPP heavy duty
timing belt, RPP5



DH

Dowel pin, Solid DIN
6325



DCA

Suction cup, 1.5
bellows, natural
rubber

Complementary products



ACM_AZ

Mounting bracket for
bonnet fastener, Hook



ACM_DZ

Clip for bonnet
fastener, Clip



GEC

Rubber latch clamp
with strike plate,
Lockable