

- Manually fastened using a hook
- Split pin supplied
- Material :
Black rubber, Shore 65/70

Advantage

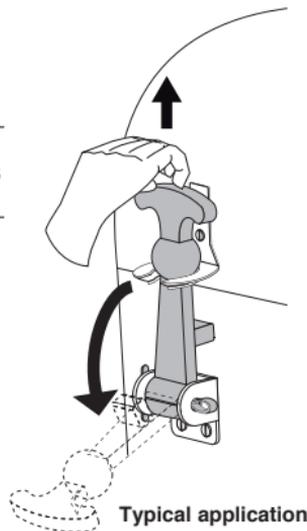
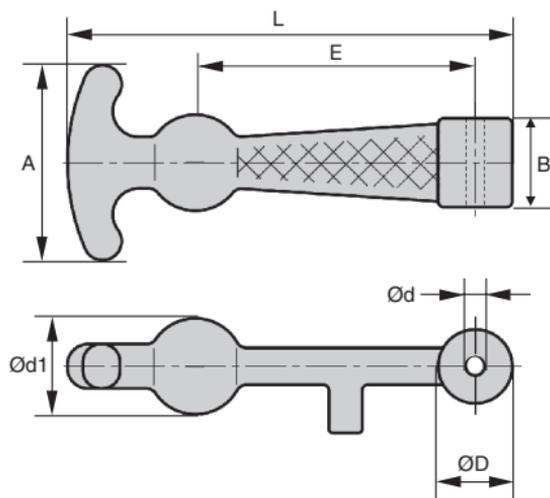
- Very easy to use

Info.

- Not sold individually, please contact us for details

Accessories

- See ACM-AZ-32 and ACM-BZ-32 hooks and ACM-BZ-23 bracket (t.imagetome1 p.156, t.imagetome1 p.157)

**DISCOUNTS**

Qty	1+	51+	101+	250+
Disc.	List	-10%	-15%	On request

Part number	E			A	B	ØD	Ød1	Ød	Stock*	Price each 1 to 50
	L	At rest	Under tension							
ACM-TRI-120	120	74	77 ⁺²	54	25	19	25	4	✓	4,10 €

*Depending on availability - Dimensions in mm

Our other products



VRC1

Retaining clamp,
single sided, Single
sided



PSG125

Spur gear - precision
range, Case hardened
steel 20NCD2



BUH77

Motor-gearbox 12V
and 24V DC, from 0.1
to 2 Nm



PDM_PDV

Detectable plastic
palm grip, blue
thermoplastic



WJUM20

Drylin® W bearing
block, Slide



RVM25

Manually operated
gearbox, Bevel



PSG125S

Spur gear - precision
range, Stainless steel
303



MBEX

Hexagonal ended
handle, Hexagonal
ended handle



HCA

Magnetic screw with
socket, Steel



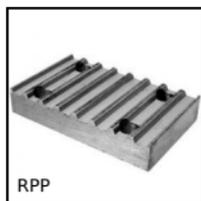
SVG

Adjustable latch
clamp with strike
plate, Stroke from



PDR-RD

Mounting feet with
integrated castors,
Offset castor



RPP

Connecting plate for
RPP type timing belts,
RRP5

Complementary products



ACM_AZ

Mounting bracket for
bonnet fastener, Hook



ACM_DZ

Clip for bonnet
fastener, Clip



GEC

Rubber latch clamp
with strike plate,
Lockable