

- Manually fastened using a hook
- Split pin supplied
- Material :
Black rubber, Shore 65/70

Advantage



- Very easy to use

Info.

- Not sold individually, please contact us for details

Accessories

- See ACM-AZ-32 and ACM-BZ-32 hooks and ACM-BZ-23 bracket (t.imagetome1 p.156, t.imagetome1 p.157)

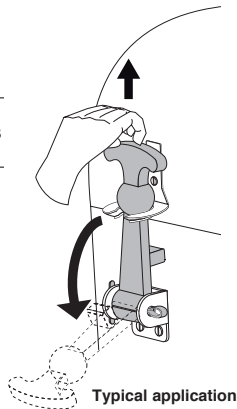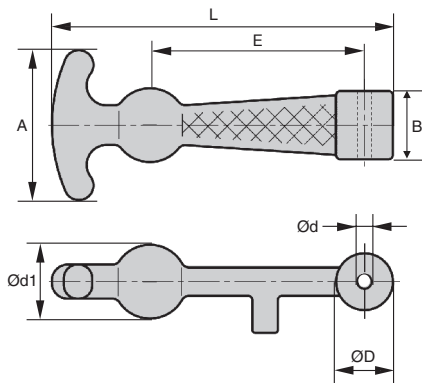
**DISCOUNTS**

Qty	1+	51+	101+	250+
Disc.	List	-10%	-15%	On request

Part number	E			A	B	ØD	Ød1	Ød	Stock*	Price each 1 to 50
	L	At rest	Under tension							
ACM-TRI-120	120	74	77 ⁺²	54	25	19	25	4	✓	4,10 €

*Depending on availability - Dimensions in mm

 Our other products



Steel bevel gear, 1:1



Straight long link stainless steel chain, Stainless steel



Magnetic screw with hexagonal head, Steel



Arm with rotating handle, Square bore



 
Parallel axis helical gear, Machined plastic (delrin)



Cap for square tube to be welded, To be welded



Ball transfer unit light duty, Light



Stop washer, Stop washer MB



Slat top chain acetal, Large range 821



Male swivelling lifting rings stainless steel,



Female wing knob, With blind thread



Adjustable support arm, Increased grip

Complementary products



Mounting bracket for bonnet fastener, Hook



Clip for bonnet fastener, Clip



Rubber latch clamp with strike plate, Lockable