

- Manually fastened using a hook
- Split pin supplied
- Material :
Black rubber, Shore 65/70

Advantage



- Very easy to use

Info.

- Not sold individually, please contact us for details

Accessories

- See ACM-AZ-32 and ACM-BZ-32 hooks and ACM-BZ-23 bracket (t.imagetome1 p.156, t.imagetome1 p.157)

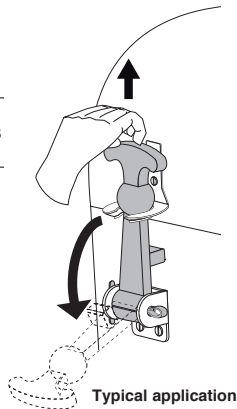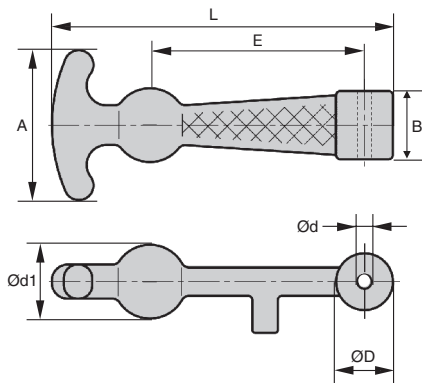

DISCOUNTS

Qty	1+	51+	101+	250+
Disc.	List	-10%	-15%	On request

Part number	E			A	B	ØD	Ød1	Ød	Stock*	Price each 1 to 50
	L	At rest	Under tension							
ACM-TRI-120	120	74	77 ⁺²	54	25	19	25	4	✓	4,10 €

*Depending on availability - Dimensions in mm

Our other products



CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...



T10courroie

T type timing belt, T10 Steel cored polyurethane



PRES4HR

Manual workbench press, Force up to 600kg



BAG

Steel Clamping collar, Steel



PPS

Lifting ring, Universal threaded




CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...



SVT20

 Screwjack with travelling screw, with translating screw



LWH

High rigidity linear slide, Chariot - from 9320 N to 71300 N



VTLF

3 lobed handle, Polyamide - Brass



MPB

Hexagonal spacer, Brass



CHAR6035

Spring hinge, screwed/welded



MDR

Dee shackle with eye bolt, Steel

Complementary products



ACM_AZ

Mounting bracket for bonnet fastener, Hook



ACM_DZ

Clip for bonnet fastener, Clip



GEC

Rubber latch clamp with strike plate, Lockable