

- Manually fastened using a hook
- Split pin supplied
- Material :
Black rubber, Shore 65/70

Advantage



- Very easy to use

Info.

- Not sold individually, please contact us for details

Accessories

- See ACM-AZ-32 and ACM-BZ-32 hooks and ACM-BZ-23 bracket (t.imagetome1 p.156, t.imagetome1 p.157)

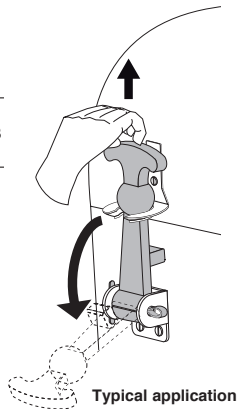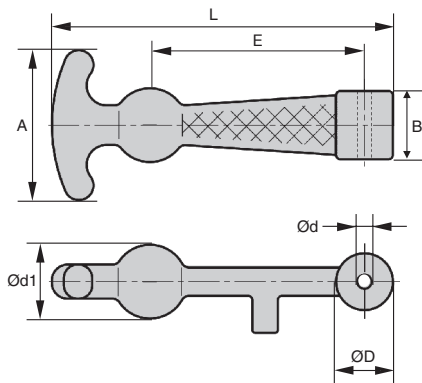

DISCOUNTS

Qty	1+	51+	101+	250+
Disc.	List	-10%	-15%	On request

Part number	E			A	B	ØD	Ød1	Ød	Stock*	Price each 1 to 50
	L	At rest	Under tension							
ACM-TRI-120	120	74	77 ⁺²	54	25	19	25	4	✓	4,10 €

*Depending on availability - Dimensions in mm

Our other products



HLUMss

Revolving handle for handwheel, Stainless steel 316



EHD08-3

Internal epicyclic servo reducers, from 20 to 50 Nm



ZG0

Plastic spur gear, Machined plastic (delrin)



WBGV

Lifting ring, Threaded




CAP821

Slat top chain acetal, Large range 821



PCS50

 Chain sprocket - steel, 12.7mm (DIN08B-1)




PRT

Rotary table Iglidur®, Iglidur®, aluminium and stainless steel



RESC

 Retractable castor for aluminium profile, Retractable castor



PF55

Worm and wheel gear reducer, up to 57 Nm



GLP

Small 6 lobe threaded handle - male,



HW_HT

Half-rail guide, Rail



PR85

Articulated foot Ø83, Ø 83

Complementary products



ACM_AZ

Mounting bracket for bonnet fastener, Hook



ACM_DZ

Clip for bonnet fastener, Clip



GEC

Rubber latch clamp with strike plate, Lockable