

- Manually fastened using a hook
- Split pin supplied
- Material :
Black rubber, Shore 65/70

Advantage


- Very easy to use

Accessories

- See ACM-AZ-32 and ACM-BZ-32 hooks and ACM-BZ-23 bracket

Info.

- Not sold individually, please contact us for details

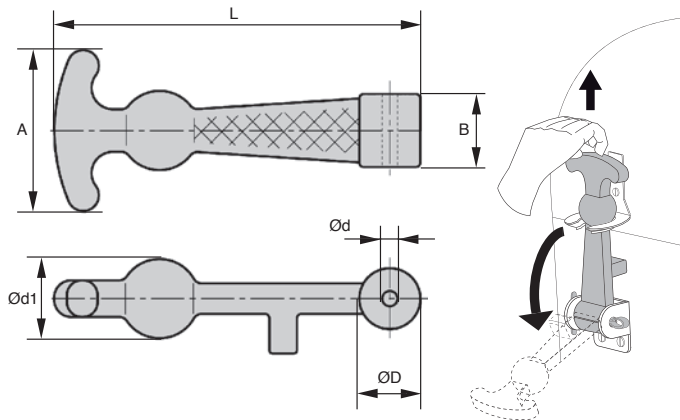

DISCOUNTS

Qty	1+	51+	101+	250+
Disc.	List	-10%	-15%	On request

Part number	L	A	B	ØD	Ød1	Ød	Stock*	Price each 1 to 50
ACM-TRI-120	120	54	25	19	25	4	✓	3,49 €

*Depending on availability - Dimensions in mm

Our other products



PRF-SCREEN-4

Screen support,
Support with 4 axes of
rotation



CLG15-ALI

Spur gear, Moulded
blue plastic (nylon)



PW_PWG1

Worm - precision
range, Steel



RJUM05

Housing for linear
bearing, Closed - Long



PLN

Spacer, Thermoplastic



PXHG1

Crossed helical gear -
precision range,
35NCD6 Pre-hardened
steel



 
CMA

Eye bolt, Steel



B_ECO

Bevel gear - Steel
C43, 1:1



B

Bevel gear - Steel
60C40, 1:1



RBS

Disc springs, Steel



TRM

Round spur rack,
Steel - module 1-6



ACLERP

Roller block, Without
guide rail

Complementary products



ACM_AZ

Manual bonnet
fastener, Hook



ACM_DZ

Manual bonnet
fastener, Clip



GEC

Rubber latch clamp
with strike plate,
Lockable