

Male eye bolt conforms to **DIN580** **Sta** **Ste** **DIN**


ADLM

Steel or stainless steel

- **ISO thread**
- **Material:**
Black stamped steel
Stainless steel 316

Mounting

- For safe and correct assembly: Chamfer the hole into which the bolt will screw or use washers to ensure correct seating.
- Before assembly, clean the threads and corresponding tapped holes
- Screw lifting eye in fully
- The load should be lifted in the direction of the thread, +/- 20° and the pulling force should be along the axial plane of the eye.
- The use of these lifting eyes at an angle greater than 45° is not allowed.
- When the load to be lifted is aluminium, avoid leaving the eyes screwed in for long periods to avoid possible corrosion.

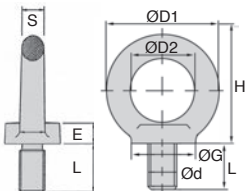

Steel eye bolt



Stainless steel eye bolt

Info.

*SWL: SAFE WORKING LOAD
The Safe Working Load is calculated by dividing the breaking Strength by a factor of safety of 5.

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request

Part number	Ød	L	H	ØD1	ØD2	ØG	E	ØS	CMU	CMU at Weightt	Price each		
									(kg)	45° (kg)		(kg)	Stock*
Steel eye bolt													
ADL-6M	M6	13	36	36	20	20	6	8	90	60	0,060	✓	2,16 €
ADL-8M	M8	13	38	36	20	21	7	9	140	95	0,060	✓	2,20 €
ADL-10M	M10	16	46	45	24	26	9	10	230	170	0,110	✓	2,68 €
ADL-12M	M12	19	56	55	29	30	12	11	340	240	0,170	✓	3,27 €
ADL-16M	M16	28	65	64	36	35	12	14	700	500	0,290	✓	5,06 €
ADL-20M	M20	30	74	72	40	40	14	17	1200	830	0,450	✓	7,54 €
ADL-24M	M24	36	92	89	49	51	18	21	1800	1270	0,880	✓	12,83 €
ADL-30M	M30	43	111	108	60	65	23	25	3200	2300	1,640	✓	24,33 €
ADL-36M	M36	54	131	126	68	80	24	29	4600	3300	2,710	-	42,30 €
ADL-42M	M42	61	153	148	79	90	33	35	6300	4500	4,250	-	80,02 €
ADL-48M	M48	68	168	166	90	100	35	38	8600	6100	6,200	-	138,68 €
Stainless steel eye bolt													
ADL-6M/SS	M6	13	-	35	20	20	7	8	180	-	0,050	✓	7,22 €
ADL-8M/SS	M8	13	-	36	20	20	6	8	300	-	0,060	✓	7,70 €
ADL-10M/SS	M10	17	-	45	25	25	8	10	500	-	0,115	✓	12,99 €
ADL-12M/SS	M12	20	-	54	30	30	10	12	800	-	0,190	✓	18,03 €
ADL-14M/SS	M14	20	-	54	30	30	10	12	1100	-	0,190	✓	20,74 €
ADL-16M/SS	M16	27	-	63	35	35	12	14	1500	-	0,280	✓	26,22 F
ADL-20M/SS	M20	30	-	72	40	40	14	16	2400	-	0,450	-	43,74 €
ADL-24M/SS	M24	35	-	90	50	50	17	22	3600	-	0,900	-	84,41 €

*Depending on availability - Dimensions in mm

Our other products



F7-E

Multifunction display,
With external sensor



NDS20

Double cross clamp,
Crossed



INS

Self tapping steel
insert, Steel



DCG

Suction cup, 2.5
bellows, silicon




NT62

Spur gear coaxial
gearbox, from 6 to 18
Nm - In-line



HG6

 Steel spur gear, Steel
20NCD2



T2

T type timing belt,
T2.5 Steel cored
polyurethane



PRF1945

Standard aluminium
profile, 19 x 45 mm



PTAF100-PAMF100

Articulated fixable
foot with pressed



SRG

Adjustable latch
clamp with strike



GLP

Small 6 lobe threaded
handle - male,



G1

Steel spur gear, Steel
20NCD2

Complementary products



ADL_M

Male eye bolt
conforms to DIN580,
Stainless steel



ADL_F

Female eye bolt
conforms to DIN582,
Steel



VRSF

Male swivelling lifting
ring, Male swivelling



VRM

Female swivelling
lifting rings, Female
swivelling