

# Male eye bolt conforms to **DIN580** **Sta** **Ste** **DIN**


## ADLM

## Steel or stainless steel

- **ISO thread**
- **Material:**  
Black stamped steel  
Stainless steel 316

### Mounting

- For safe and correct assembly: Chamfer the hole into which the bolt will screw or use washers to ensure correct seating.
- Before assembly, clean the threads and corresponding tapped holes
- Screw lifting eye in fully
- The load should be lifted in the direction of the thread, +/- 20° and the pulling force should be along the axial plane of the eye.
- The use of these lifting eyes at an angle greater than 45° is not allowed.
- When the load to be lifted is aluminium, avoid leaving the eyes screwed in for long periods to avoid possible corrosion.

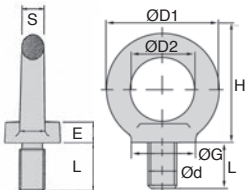

Steel eye bolt



Stainless steel eye bolt

### Info.

\*SWL: SAFE WORKING LOAD  
The Safe Working Load is calculated by dividing the breaking Strength by a factor of safety of 5.

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request

Part number	Ød	L	H	ØD1	ØD2	ØG	E	ØS	CMU	CMU at Weightt	Price each		
									(kg)	45° (kg)		(kg)	Stock*
<b>Steel eye bolt</b>													
ADL-6M	M6	13	36	36	20	20	6	8	90	60	0,060	✓	2,16 €
ADL-8M	M8	13	38	36	20	21	7	9	140	95	0,060	✓	2,20 €
ADL-10M	M10	16	46	45	24	26	9	10	230	170	0,110	✓	2,68 €
ADL-12M	M12	19	56	55	29	30	12	11	340	240	0,170	✓	3,27 €
ADL-16M	M16	28	65	64	36	35	12	14	700	500	0,290	✓	5,06 €
ADL-20M	M20	30	74	72	40	40	14	17	1200	830	0,450	✓	7,54 €
ADL-24M	M24	36	92	89	49	51	18	21	1800	1270	0,880	✓	12,83 €
ADL-30M	M30	43	111	108	60	65	23	25	3200	2300	1,640	✓	24,33 €
ADL-36M	M36	54	131	126	68	80	24	29	4600	3300	2,710	-	42,30 €
ADL-42M	M42	61	153	148	79	90	33	35	6300	4500	4,250	-	80,02 €
ADL-48M	M48	68	168	166	90	100	35	38	8600	6100	6,200	-	138,68 €
<b>Stainless steel eye bolt</b>													
ADL-6M/SS	M6	13	-	35	20	20	7	8	180	-	0,050	✓	7,22 €
ADL-8M/SS	M8	13	-	36	20	20	6	8	300	-	0,060	✓	7,70 €
ADL-10M/SS	M10	17	-	45	25	25	8	10	500	-	0,115	✓	12,99 €
ADL-12M/SS	M12	20	-	54	30	30	10	12	800	-	0,190	✓	18,03 €
ADL-14M/SS	M14	20	-	54	30	30	10	12	1100	-	0,190	✓	20,74 €
ADL-16M/SS	M16	27	-	63	35	35	12	14	1500	-	0,280	✓	26,22 F
ADL-20M/SS	M20	30	-	72	40	40	14	16	2400	-	0,450	-	43,74 €
ADL-24M/SS	M24	35	-	90	50	50	17	22	3600	-	0,900	-	84,41 €

\*Depending on availability - Dimensions in mm

## Our other products



ZG3

Plastic spur gear,  
Machined plastic  
(delrin)



PW\_PWG1

Wheel - precision  
range, Bronze



DOMI50

Accessories, Turntable



GE14

Toggle latches, With  
padlock-holder



PW\_PWG2

Wheel - precision  
range, Bronze



CHAC4040NP

Square hinge with  
riveted pin, not  
drilled, Square with  
riveted pin,...



CHTRP

Single and dual  
output gearboxes, Up  
to 9,1 Nm




PRF-CHAR-POU

Tool holder for  
aluminium profile,  
Moveable tool holder



PSPD18

 Flexible tube handle,  
Black PVC



TBL

Mini leadscrew table  
with metric thread,



PT820

Drive sprocket for slat  
top chain, Ranges 820



T5P\_T10P

Connecting plate for T  
type timing belts, T10

## Complementary products



ADL\_M

Male eye bolt  
conforms to DIN580,  
Stainless steel



ADL\_F

Female eye bolt  
conforms to DIN582,  
Steel



VRSF

Male swivelling lifting  
ring, Male swivelling



VRM

Female swivelling  
lifting rings, Female  
swivelling