



Rigid coupling with keyway

AF

Set screw fixing

- With keyway
- Material:
Steel

Set screw

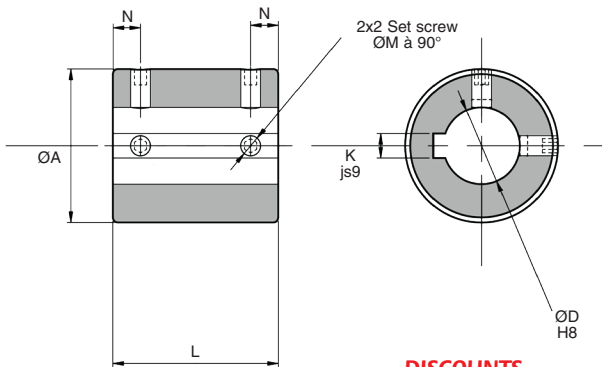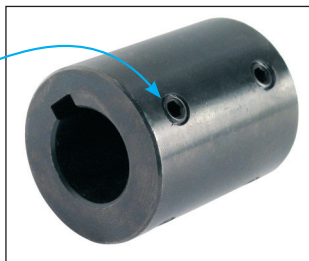

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	ØD	Keyway K	ØA	L	Set screw ØM	N	Stock*	Price each 1 à 5
AF10	10	3	20	30	M4	6	✓	86,14 €
AF12	12	4	28	36	M5	7	✓	86,14 €
AF15	15	5	28	36	M5	8	✓	86,14 €
AF20	20	6	32	40	M6	10	✓	108,83 €
AF25	25	8	40	54	M8	12	✓	126,61 €
AF30	30	8	50	54	M8	12	✓	139,26 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2021


www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



End cap with threaded insert for round tube, With threaded insert

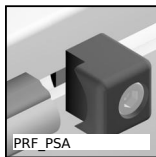

Shaft support for aluminium profile, Shaft stop



AT type timing belt per metre, AT5 Steel cored polyurethane



24V DC power supply, 10 A



High rigidity linear slide, Chariot - from 9320 N to 71300 N



Adjustable Stainless steel cam lever, Male



Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel



Articulated levelling foot, pressed base Ø100, Ø 100



Rigging screw (hook/hook), Steel



Right angled gearbox, from 1.32 to 4.40 Nm



Joining plate for aluminium profile, Joint plate - 86x86 mm



Adjustable latch clamp with strike plate, Stroke from 106,7mm to 121...

Complementary products



2 part rigid shaft clamp, Clamping jaw