
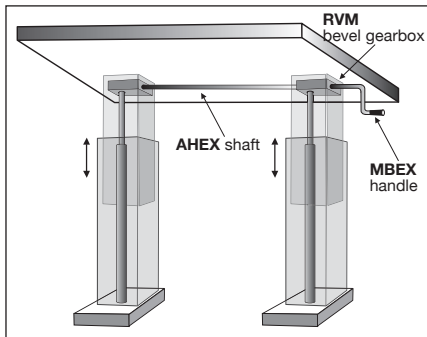


Hexagonal shaft **DIN176**

AHEX For manually operated bevel gearbox

- Hexagonal shaft for use with the RAM and RVM bevel gearbox ranges
- Cut to required length
- Material:
Steel

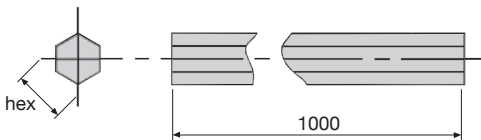

Typical application

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Profil	Length (mm)	Price each 1 to 9
AHEX6-1000	hex 6mm	1000	24,64 €
AHEX7-1000	hex 7mm	1000	29,36 €
AHEX9-1000	hex 9mm	1000	29,36 €

Dimensions in mm

Our other products



NCT_AT
Variable angle
connector, Variable
angle



PCS62
Chain sprocket - steel,
15.875 (DIN 10B-1)



UCFL_SS
Stainless steel flanged
bearing, Stainless
steel




GARQT
Quarter turn lock pin
for clamping, Quarter
turn




E20
Right angle helical
reducers, from 0.60 to
3.84 Nm



CPAS
Stay with safety
catch, Opens upward

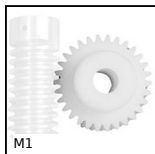

M1
Worm and wheel set,
Machined plastic
(delrin)

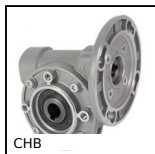

CHB
Worm and wheel gear
reducer, up to 22 Nm



RFVcap
Stainless steel
protective cover,



gt64r
Rotating bent lever
with spring, Increased



HRV
V- rail guidance
Simple Select®



SSB
Stainless steel bevel
gear, 1:1

Complementary products



RAM30
Manual bevel
gearbox, Bevel



RVM14
Manual worm and
wheel gearbox,
Worm/wheel



RVM25
Manually operated
gearbox, Bevel



RAM35
Manual bevel
gearbox, Bevel