
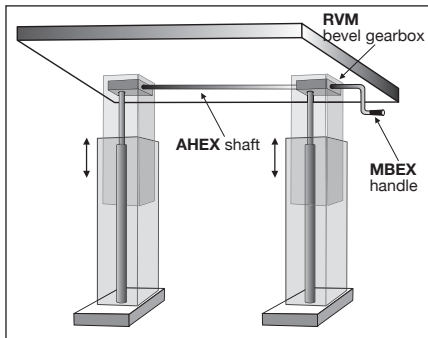


Hexagonal shaft **DIN176**

AHEX For manually operated bevel gearbox

- Hexagonal shaft for use with the RAM and RVM bevel gearbox ranges
- Cut to required length
- Material:
Steel

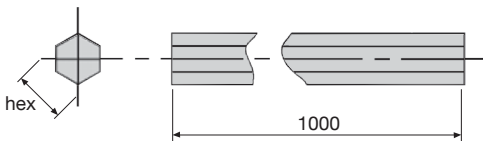

Typical application

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Profil	Length	Price each
		(mm)	1 to 9
AHEX6-1000	hex 6mm	1000	24,64 €
AHEX7-1000	hex 7mm	1000	29,36 €
AHEX9-1000	hex 9mm	1000	29,36 €

Dimensions in mm

Our other products



HSSss

Stainless steel shoulder screw ISO7379, Stainless steel ISO 7379



SDCss

Positioning sleeve for indexing pin, For pin Ø4 to Ø12



SLVHlok

Vertical toggle clamp, Vertical toggle clamp / horizontal foot



BAC105

Storage bin, 8mm



DIA

Ring operated locking bolt, with ring



COA-COG

Surface mounting plate, Surface mounting plate for ball joint



SVT5

Screwjack with travelling screw, with translating screw



UGH50

H Type Guide units, For Ø50 actuators



EP7

Electronic digital position indicator, 5 numbers



CQA20

Accessory for adjustment slide-system, 20



PRF_ROUL

Castor for aluminium profile, No brake



AT10-25ECO

AT type timing pulley, Economy range - AT10 aluminium

Complementary products



RAM30

Manual bevel gearbox, Bevel



RVM14

Manual worm and wheel gearbox, Worm/wheel



RVM25

Manually operated gearbox, Bevel



RAM35

Manual bevel gearbox, Bevel