



# Protective cap

Plastic

APBBOU

- To protect adjusting rods APB-F and APB-T
- Material: flexible PVC
- Black
- Weight: 0.01 kg

## Info.


- Not sold individually, please contact us for details

## Accessories

- Adjusting rod APB-T or APB-F



With adjusting rod APB

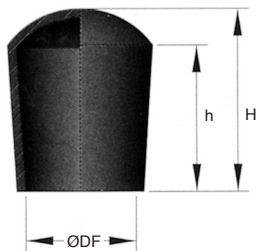

## DISCOUNTS

Qty	1+	41+	100+
Disc.	List	-5%	On request

Part number	For shaft DF	h	H	Stock*	Price each 1 to 40
APB10-BOU	10	15	18	✓	0,37 €
APB12-BOU	12	16	20	✓	0,37 €
APB14-BOU	14	17	21	✓	0,37 €
APB15-BOU	15	17	21	-	0,37 €
APB16-BOU	16	18	23	✓	0,37 €

\*Depending on availability - Dimensions in mm

## Our other products



WING  
Manually tightened wing nut, Steel (ANSI B18-17)



 
PAMF100EB  
Articulated foot with sheet metal base  
Ø100, Articulated foot



SLB  
Indexing plunger, steel class 5.8



T10courroie  
T type timing belt, T10 Steel cored polyurethane



PF40  
Worm and wheel gear reducer, up to 18 Nm



GMK17\_RG  
Joint for guiding profile, Rounded



BMF  
Knurled knob - female, Knurled - blind



E30  
Right angle helical reducers, from 1.50 to 9 Nm



MSP23  
Masterplate® glueable insert Ø23, Cylindrical Ø23 with



GPLss  
Brush, stainless steel



LFM2  
Steel leadscrew, Medium carbon steel - 2 threads



BTC20\_10  
End cap for rectangular tube, Standard

## Complementary products



APB\_T  
Adjusting rod for clamp - Female, Bored



APB\_F  
Adjusting rod for clamp - Male, Threaded



GMC\_GMK\_BR  
Guiding profile clamp, Flat or rounded