



Protective cap

Plastic

APBBOU

- To protect adjusting rods APB-F and APB-T
- Material: flexible PVC
- Black
- Weight: 0.01 kg

Info.


- Not sold individually, please contact us for details

Accessories

- Adjusting rod APB-T or APB-F



With adjusting rod APB

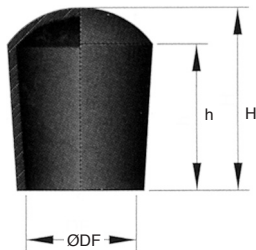


DISCOUNTS

Qty	1+	41+	100+
Disc.	List	-5%	On request

Part number	For shaft DF	h	H	Stock*	Price each 1 to 40
APB10-BOU	10	15	18	✓	0,37 €
APB12-BOU	12	16	20	✓	0,37 €
APB14-BOU	14	17	21	✓	0,37 €
APB15-BOU	15	17	21	-	0,37 €
APB16-BOU	16	18	23	✓	0,37 €

*Depending on availability - Dimensions in mm

Our other products

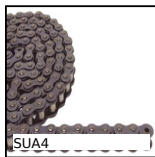

SUA4
Single chain supplied by the metre, Steel



PRF-GPB
Guide for aluminium profile, Rail for 8mm wide slots



HFL
One way needle bearing, Needle bearing



SA_SAKH
Housing for linear bearing, Closed - light load



FAD
Threaded swivel feet, Swivel feet without anti-slip plate



NDS20
Double cross clamp, Parallel



 
MFB
Flexible bellows coupling, Aluminium and Bronze - With set screw



RURp
Wheel pivoting with plate, Polyurethane - Aluminium rim (Free running)




BPHT
Ball transfer unit bolt fitting, Heavy



BETASS
Hitch pin, Hitch



PO
Pull handle - Multi-sector, Smooth hole

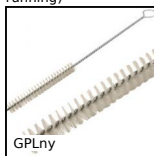

GPLny
Brush, nylon

Complementary products



APB_T
Adjusting rod for clamp - Female, Bored



APB_F
Adjusting rod for clamp - Male, Threaded



GMC_GMK_BR
Guiding profile clamp, Flat or rounded