

Threaded rod for clamp



APBF

Stainless steel

- To hold GMC-BR and GMK-BR clamps in position

- Material: stainless steel

Info.

- Not sold individually, please contact us for details

- APB15-100F has a fixing hole, not a flat section

Accessories




- Clamps GMC-BR, GMK-BR

- Protective cap APB-BOU

- Guide supports SDG, SDG/SS



With protective cap APB

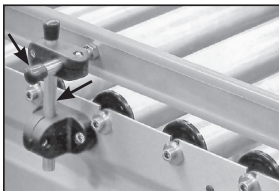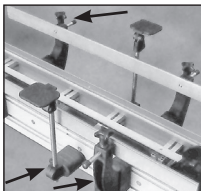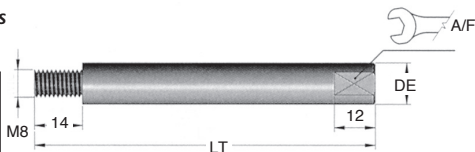

Typical application

DISCOUNTS

Qty	1+	41+	101+
Disc.	List	-5%	On request

Part number	DE	Flat size A/F	LT	Weight (kg)	Stock*	Price each 1 to 40
APB10-110F	10	8	110	0,07	✓	7,42 €
APB12-100F	12	10	100	0,09	✓	5,91 €
APB14-100F	14	12	100	0,12	✓	7,42 €
APB15-100F	15	12	100	0,14	✓	9,30 €
APB16-100F	16	14	100	0,16	✓	9,44 €

*Depending on availability - Dimensions in mm



Bored rod for clamp

Stainless steel

APBT

- Material: stainless steel

Info.




- Not sold individually, please contact us for details

Accessories

- Protective cap APB-BOU
- Guide supports SDG, SDG/SS



With protective cap
APB-BOU

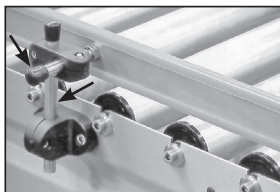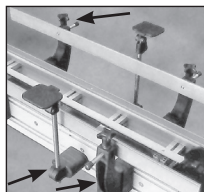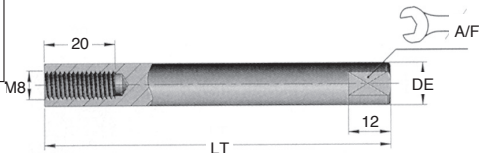

Typical application

DISCOUNTS

Qty	1+	41+	101+
Disc.	List	-5%	On request

Part number	DE	Flat size A/F	LT	Weight (kg)	Stock*	Price each 1 to 40
APB12-100T	12	10	100	0,09	✓	6,93 €
APB14-100T	14	12	100	0,12	✓	7,92 €
APB15-100T	15	12	100	0,14	-	9,61 €
APB16-100T	16	14	100	0,16	-	9,61 €


*Depending on availability - Dimensions in mm

Our other products



PPOss

Pad eye on mounting plate oval, Stainless steel

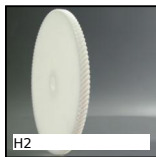

H2

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



PSG125

Spur gear - precision range, Case hardened steel 20NCD2



G3-ECO

Eco range Spur gear, Steel C45



VRBS

Folding lifting ring for welding, Folding - for welding



SRG

Adjustable latch clamp with strike plate, Stroke from 78mm to 90mm



NCT

Square tube connector, Fixed angle



BUT

Panel stop, Panel stop



PTAF80-PAMF80

Articulated fixable foot with pressed base Ø80, Ø 80



ZG0

Plastic spur gear, Machined plastic (delrin)



TPEpbd

Castor for aluminium profile, Swivel with brake



DER90

Stainless steel AC asynchronous motor 1.1 - 1.5kW, 1.1 to 1.5kW

Complementary products



GMC_GMK_BR

Guiding profile clamp, Flat or rounded



APB_BOU

Protective cap, Safety cap



BSPT

Single rod clip, Round



STL

Guidance brush - Rail, Rail