

# Threaded rod for clamp



## APBF

## Stainless steel

- To hold GMC-BR and GMK-BR clamps in position

- Material: stainless steel

### Info.

- Not sold individually, please contact us for details

- APB15-100F has a fixing hole, not a flat section

### Accessories




- Clamps GMC-BR, GMK-BR

- Protective cap APB-BOU

- Guide supports SDG, SDG/SS



With protective cap APB

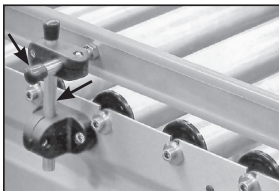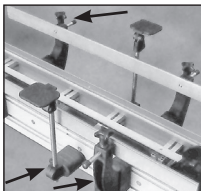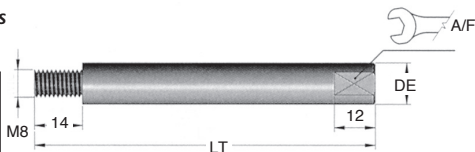

Typical application

### DISCOUNTS

Qty	1+	41+	101+
Disc.	List	-5%	On request

Part number	DE	Flat size A/F	LT	Weight (kg)	Stock*	Price each 1 to 40
APB10-110F	10	8	110	0,07	✓	7,42 €
APB12-100F	12	10	100	0,09	✓	5,91 €
APB14-100F	14	12	100	0,12	✓	7,42 €
APB15-100F	15	12	100	0,14	✓	9,30 €
APB16-100F	16	14	100	0,16	✓	9,44 €

\*Depending on availability - Dimensions in mm



# Bored rod for clamp

## Stainless steel

## APBT

- Material: stainless steel

### Info.




- Not sold individually, please contact us for details

### Accessories

- Protective cap APB-BOU  
- Guide supports SDG, SDG/SS



With protective cap  
APB-BOU

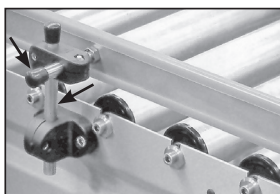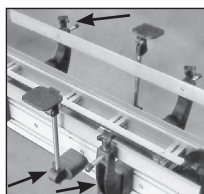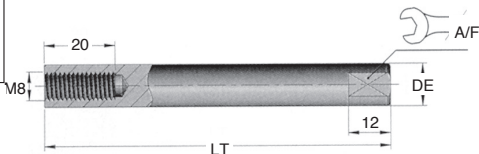

Typical application

### DISCOUNTS

Qty	1+	41+	101+
Disc.	List	-5%	On request

Part number	DE	Flat size A/F	LT	Weight (kg)	Stock*	Price each 1 to 40
APB12-100T	12	10	100	0,09	✓	6,93 €
APB14-100T	14	12	100	0,12	✓	7,92 €
APB15-100T	15	12	100	0,14	-	9,61 €
APB16-100T	16	14	100	0,16	-	9,61 €

\*Depending on availability - Dimensions in mm

## Our other products



NDS20  
Double cross clamp,  
Crossed



BOX-TOR-A  
Box set of Nitrile O-  
rings in nitrile, 2.90 x  
1.78mm to 28.17 x  
3.53




PRF\_PIV  
Internal hinge pin for  
aluminium profile,  
Internal hinge pin



BFDdII  
Locking pin for  
bushes, Nickel-plated  
steel



 MSP3815  
Masterplate®  
glueable insert  
rectangular,  
rectangular with nut



SCH  
Horizontal hook  
toggle clamp,  
Horizontal Hook  
clamp - steel



DHX  
Dowel pin internal  
thread, Extractable  
DIN 7979D



UCFL  
Cast iron flanged  
bearing, Cast iron




CLM  
Male clevis end,  
Stainless steel short



BLHB30  
Right angled gearbox,  
bored shafts, up to



 BUH77  
Motor-gearbox 12V  
and 24V DC, from 0.1



AC  
Strike for toggle latch,  
18mm

## Complementary products



GMC\_GMK\_BR  
Guiding profile clamp,  
Flat or rounded



APB\_BOU  
Protective cap, Safety  
cap



BSPT  
Single rod clip, Round



STL  
Guidance brush - Rail,  
Rail