

Threaded rod for clamp



APBF

Stainless steel

- To hold GMC-BR and GMK-BR clamps in position

- Material: stainless steel

Info.

- Not sold individually, please contact us for details

- APB15-100F has a fixing hole, not a flat section

Accessories




- Clamps GMC-BR, GMK-BR

- Protective cap APB-BOU

- Guide supports SDG, SDG/SS



With protective cap APB

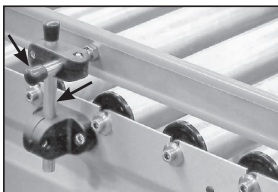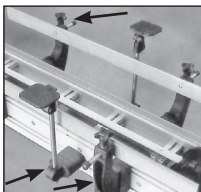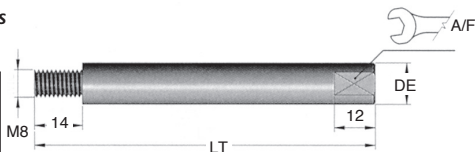

Typical application

DISCOUNTS

Qty	1+	41+	101+
Disc.	List	-5%	On request

Part number	DE	Flat size A/F	LT	Weight (kg)	Stock*	Price each 1 to 40
APB10-110F	10	8	110	0,07	✓	7,42 €
APB12-100F	12	10	100	0,09	✓	5,91 €
APB14-100F	14	12	100	0,12	✓	7,42 €
APB15-100F	15	12	100	0,14	✓	9,30 €
APB16-100F	16	14	100	0,16	✓	9,44 €

*Depending on availability - Dimensions in mm



Bored rod for clamp

Stainless steel

APBT

- Material: stainless steel

Info.




- Not sold individually, please contact us for details

Accessories

- Protective cap APB-BOU
- Guide supports SDG, SDG/SS



With protective cap
APB-BOU

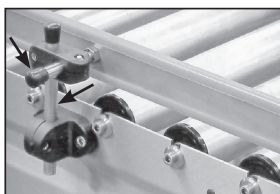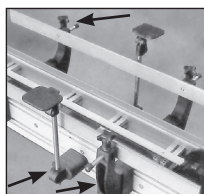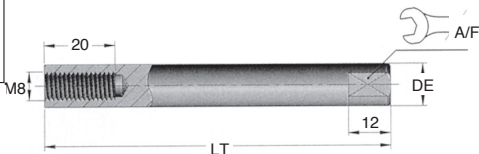

Typical application

DISCOUNTS

Qty	1+	41+	101+
Disc.	List	-5%	On request

Part number	DE	Flat size A/F	LT	Weight (kg)	Stock*	Price each 1 to 40
APB12-100T	12	10	100	0,09	✓	6,93 €
APB14-100T	14	12	100	0,12	✓	7,92 €
APB15-100T	15	12	100	0,14	-	9,61 €
APB16-100T	16	14	100	0,16	-	9,61 €

*Depending on availability - Dimensions in mm

Our other products



WW10
Drylin® W slide, slide assembly



PENV
Recessed handle, screw fixing



PSG125HC
Skive hobbled spur gears - precision range, Case hardened steel 20NCD2



G-ECO
Eco range Spur gear, Steel C45



MAX26
Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm



CHA35
Hinge for aluminium profile, Hinge



ACM_AZ
Mounting bracket for bonnet fastener, Hook



PSG05
Spur gear - precision range, Case hardened steel 20NCD2



CABma
Swaging sleeve for fitting cable, To crimp



GEC
Rubber latch clamp with strike plate,



CNA-CNG
Right angled mounting plate, Right



LOQ
Manual lock, Manual latch

Complementary products



SDG
Adjustable guide support bracket, Plastic



APB_BOU
Protective cap, Safety cap



SDG_SS
Universal adjustable guide support bracket, Stainless steel



APB_F
Adjusting rod for clamp - Male, Threaded