

# Threaded rod for clamp



## APBF

## Stainless steel

- To hold GMC-BR and GMK-BR clamps in position

- Material: stainless steel

### Info.

- Not sold individually, please contact us for details

- APB15-100F has a fixing hole, not a flat section

### Accessories




- Clamps GMC-BR, GMK-BR

- Protective cap APB-BOU

- Guide supports SDG, SDG/SS



With protective cap APB

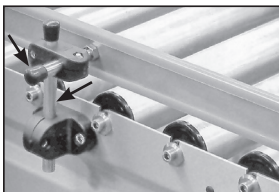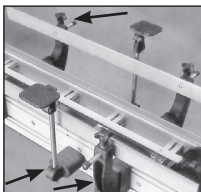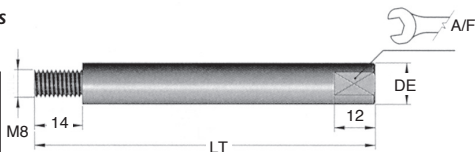

Typical application

### DISCOUNTS

Qty	1+	41+	101+
Disc.	List	-5%	On request

Part number	DE	Flat size A/F	LT	Weight (kg)	Stock*	Price each 1 to 40
APB10-110F	10	8	110	0,07	✓	7,42 €
APB12-100F	12	10	100	0,09	✓	5,91 €
APB14-100F	14	12	100	0,12	✓	7,42 €
APB15-100F	15	12	100	0,14	✓	9,30 €
APB16-100F	16	14	100	0,16	✓	9,44 €

\*Depending on availability - Dimensions in mm



# Bored rod for clamp

## Stainless steel

## APBT

- Material: stainless steel

### Info.




- Not sold individually, please contact us for details

### Accessories

- Protective cap APB-BOU  
- Guide supports SDG, SDG/SS



With protective cap  
APB-BOU

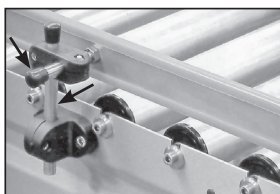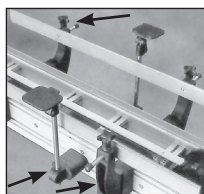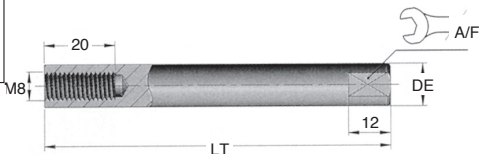

Typical application

### DISCOUNTS

Qty	1+	41+	101+
Disc.	List	-5%	On request

Part number	DE	Flat size A/F	LT	Weight (kg)	Stock*	Price each 1 to 40
APB12-100T	12	10	100	0,09	✓	6,93 €
APB14-100T	14	12	100	0,12	✓	7,92 €
APB15-100T	15	12	100	0,14	-	9,61 €
APB16-100T	16	14	100	0,16	-	9,61 €

\*Depending on availability - Dimensions in mm

## Our other products



RTTss

Locking assembly,  
Medium/high torque



CLR

Straight clevis,  
Straight clevis for use  
with a male clevis




CHM110

Worm and wheel gear  
reducer, up to 980  
Nm



PM2

 Worm and wheel set,  
Bronze



CHB

Worm and wheel gear  
reducer, up to 73 Nm



OP2

Mechanical digital  
position indicator, 3  
numbers



PSG05

Spur gear - precision  
range, Pre-hardened  
Steel 35NCD6



 
D-PAR\_SS

Stainless steel  
progressive stop,  
stainless steel



WINGbrEcrou

Manually tightened  
wing nut DIN315,  
Brass DIN 315



UGAC\_UGET

Connection for  
threaded actuator  
rod, Connection for



PTA150

Articulated levelling  
foot, pressed base  
Ø150, Ø 150



PFC

Fixed rubber levelling  
foot, Levelling support  
for small parts

## Complementary products



SDG

Adjustable guide  
support bracket,  
Plastic



APB\_BOU

Protective cap, Safety  
cap



SDG\_SS

Universal adjustable  
guide support  
bracket, Stainless  
steel



APB\_F

Adjusting rod for  
clamp - Male,  
Threaded