

- **Accessory used when assembling small structures**

- **Material:**

303/304 stainless steel

Applications


- Mounting sensors, creating small structures

Accessories

- Can be combined with **MBF** sleeves, **NSP**, **NSU** or **NDS** supports and **NRV** or **NRR** angled joints



Suitable for
food industry
applications

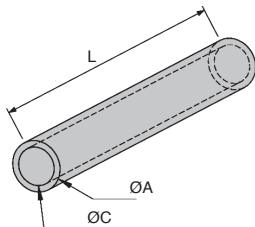

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Rod ØA	Int diam ØC	Length L (mm)	Stock*	Price each 1 to 4
APBC8-7-100	8	7	100	✓	2,89 €
APBC8-7-250	8	7	250	✓	5,25 €
APBC8-7-500	8	7	500	-	9,12 €
APBC10-9-100	10	9	100	✓	3,22 €
APBC10-9-250	10	9	250	✓	6,02 €
APBC10-9-500	10	9	500	✓	10,68 €
APBC12-10-100	12	10	100	✓	4,78 €
APBC12-10-250	12	10	250	✓	9,89 €
APBC12-10-500	12	10	500	✓	18,48 €

*Depending on availability - Dimensions in mm

Our other products



DOMI80

Accessories, Plate



CHA_GC_95S

Stainless steel garnet hinge, To be welded



BIM

Indexing plunger mini, miniature



ADL_F

Female eye bolt conforms to DIN582, Stainless steel



DOMI_MD

Domino rotary table, 40/1



G-ECO

Eco range Spur gear, Steel C45



PPF

Indexing plunger with flange, with drilled flange



ZB

Shaft for linear guides, Hardened ground stainless steel



ARTE

Flexible bush, For multi-directional loads



BOX-SHNA

Hexagonal nut - DIN934, Box set of



PR882

Idler sprocket for slat top chain, Range 882



BLHM70

Right angled gearbox, up to 128 Nm

Complementary products



MBF

Threaded blocking clamp, Threaded locking clamp



NSP

Right angled support clamp, Right angled support clamp



NSU

Universal 90° support clamp, Universal 90° support clamp



NRV

Orthogonal support clamp, Orthogonal support clamp