

Round rod

Sta Stock

APBC

Easy to assemble/adjust

- Accessory used when assembling small structures

- Material:

303/304 stainless steel

Applications


- Mounting sensors, creating small structures

Accessories

- Can be combined with **MBF** sleeves, **NSP**, **NSU** or **NDS** supports and **NRV** or **NRR** angled joints



Suitable for
food industry
applications

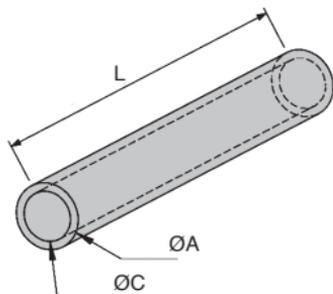

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Rod ØA	Int diam ØC	Length L (mm)	Stock*	Price each 1 to 4
APBC8-7-100	8	7	100	✓	2,89 €
APBC8-7-250	8	7	250	✓	5,25 €
APBC8-7-500	8	7	500	-	9,12 €
APBC10-9-100	10	9	100	✓	3,22 €
APBC10-9-250	10	9	250	✓	6,02 €
APBC10-9-500	10	9	500	✓	10,68 €
APBC12-10-100	12	10	100	✓	4,78 €
APBC12-10-250	12	10	250	✓	9,89 €
APBC12-10-500	12	10	500	✓	18,48 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com


Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



SHNbr

Hexagonal nut
DIN934, Brass

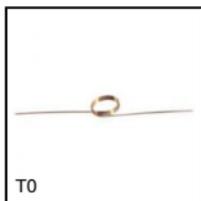

T0

Torsion spring,
Stainless steel




GSI_A

Stainless steel
adjustable gas spring,
Stainless steel



INO

Internal gear,
Machined plastic
(delrin)

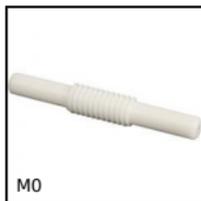

M0

Worm, Machined
plastic (delrin)



MXH

Hexagonal threaded
sleeve, Hexagonal -
steel



PPRss

Pad eye on mounting
plate round, Stainless
steel



M1

Worm , Hardened
steel



TPEpbd

Castor for aluminium
profile, Swivel with
brake



PTA50

Articulated levelling
foot, pressed base
Ø50, 4000N



SVG

Adjustable latch
clamp with strike
plate, Stroke from
82mm to 92mm



BOX-TOR-G

Box set of Nitrile O-
rings in nitrile, 3.00 x
1.50mm to 30.20 x
3.00

Complementary products



MBF

Threaded blocking
clamp, Threaded
locking clamp



NSP

Right angled support
clamp, Right angled
support clamp



NSU

Universal 90° support
clamp, Universal 90°
support clamp



NRV

Orthogonal support
clamp, Orthogonal
support clamp