

Round rod

Sta Stock

APBC

Easy to assemble/adjust

- Accessory used when assembling small structures

- Material:

303/304 stainless steel

Applications


- Mounting sensors, creating small structures

Accessories

- Can be combined with **MBF** sleeves, **NSP**, **NSU** or **NDS** supports and **NRV** or **NRR** angled joints



Suitable for
food industry
applications

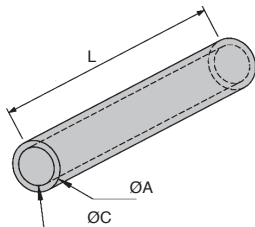

DISCOUNTS

| Qty | 1+ | 5+ | 10+ | 20+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | Rod ØA | Int diam ØC | Length L (mm) | Stock* | Price each 1 to 4 |
|---------------|--------|-------------|---------------|--------|-------------------|
| APBC8-7-100 | 8 | 7 | 100 | ✓ | 2,89 € |
| APBC8-7-250 | 8 | 7 | 250 | ✓ | 5,25 € |
| APBC8-7-500 | 8 | 7 | 500 | - | 9,12 € |
| APBC10-9-100 | 10 | 9 | 100 | ✓ | 3,22 € |
| APBC10-9-250 | 10 | 9 | 250 | ✓ | 6,02 € |
| APBC10-9-500 | 10 | 9 | 500 | ✓ | 10,68 € |
| APBC12-10-100 | 12 | 10 | 100 | ✓ | 4,78 € |
| APBC12-10-250 | 12 | 10 | 250 | ✓ | 9,89 € |
| APBC12-10-500 | 12 | 10 | 500 | ✓ | 18,48 € |

*Depending on availability - Dimensions in mm

 
HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



MR_MMR
Metric section rack,
Steel



AT10-BAR
AT type tooth bar
stock, AT10



PTA50
Articulated levelling
foot, pressed base
Ø50, Ø 50



MHXred
Reducing sleeve
male/female,
Hexagonal - steel



DHX
Dowel pin internal
thread, Extractable
DIN 7979D



gt64r
Rotating bent lever
with spring, Increased
fitting tolerances



RESC
Retractable castor for
aluminium profile,
Retractable castor



WING
Manually tightened
wing nut, Steel (ANSI
B18-17)



CFS
Miniature cam
follower, Miniature



BABpss
301 Stainless steel
ball pin, Stainless



GMK17_BR
Clamp for guiding
profile, Rounded only



PRF_VTM
Hammerhead screw,
Hammerhead screw

Complementary products



MBF
Threaded blocking
clamp, Threaded
locking clamp



NSP
Right angled support
clamp, Right angled
support clamp



NSU
Universal 90° support
clamp, Universal 90°
support clamp



NRV
Orthogonal support
clamp, Orthogonal
support clamp