

- Accessory used when assembling small structures

- Material:

303/304 stainless steel

Applications


- Mounting sensors, creating small structures

Accessories

- Can be combined with **MBF** sleeves, **NSP**, **NSU** or **NDS** supports and **NRV** or **NRR** angled joints



Suitable for
food industry
applications

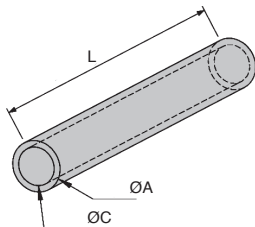

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Rod ØA	Int diam ØC	Length L (mm)	Stock*	Price each 1 to 4
APBC8-7-100	8	7	100	✓	2,89 €
APBC8-7-250	8	7	250	✓	5,25 €
APBC8-7-500	8	7	500	-	9,12 €
APBC10-9-100	10	9	100	✓	3,22 €
APBC10-9-250	10	9	250	✓	6,02 €
APBC10-9-500	10	9	500	✓	10,68 €
APBC12-10-100	12	10	100	✓	4,78 €
APBC12-10-250	12	10	250	✓	9,89 €
APBC12-10-500	12	10	500	✓	18,48 €

*Depending on availability - Dimensions in mm

Our other products



BFDdII
Locking pin for bushes, Nickel-plated steel



ZG1
Plastic spur gear, Machined plastic (delrin)



JCSss
Single stainless steel universal joint, Low duty



CHAGC-AL
Screw-in garnet hinge, Screw-on



BAN
Angular clamp, Adjustable



BLHB60
Right angled gearbox, bored shafts, up to 70 Nm



FB_ECO
Eco. range steel bevel gear, 4:1



SRG
Adjustable latch clamp with strike plate, Stroke from 78mm to 90mm



DIA
Ring operated locking bolt, with ring



PRF_P
Anchor foot for 45x45 profile, Anchor foot



CHA_GC_14SS
Stainless steel garnet hinge, To screw



SSDB
Stainless steel bevel gear, 2:1

Complementary products



MBF
Threaded blocking clamp, Threaded locking clamp



NSP
Right angled support clamp, Right angled support clamp



NSU
Universal 90° support clamp, Universal 90° support clamp



NRV
Orthogonal support clamp, Orthogonal support clamp