

Adjusting rod for clamp - Female

APBT

Stainless steel

- Material: stainless steel

Info.



- Not sold individually, please contact us for details

Accessories

- Protective cap APB-BOU
- Guide supports SDG, SDG/SS



With protective cap
APB-BOU

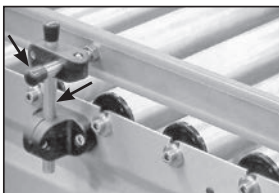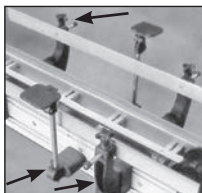

Typical application


DISCOUNTS

Qty	1+	41+	101+
Disc. List	-5%	On request	

Part number	DE	Flat size A/F	LT	Weight (kg)	Stock*	Price each 1 to 40
APB12-100T	12	10	100	0,09	✓	6,35 €
APB14-100T	14	12	100	0,12	✓	7,26 €
APB15-100T	15	12	100	0,14	-	8,80 €
APB16-100T	16	14	100	0,16	-	8,80 €

*Depending on availability - Dimensions in mm

 Our other products



TBV

Manual lifting tables,
For vertical strokes -
Ø 20 mm column




SSG1

Spur gear, Stainless
steel 304L



NT122

 Spur gear coaxial
gearbox, from 32 to
85 Nm - In-line




STL

Guidance brush,
Brush



PPF

 Indexing pin, with
drilled flange



CRM

Rack, square section,
Nylon



F7-P-AM

Multifunction display,
Magnetic ring



MEB-ALI

Moulded plastic bevel
gear (blue nylon), 1:1



CHAE6555

Decorative hinges,
Aluminium



CABma

Rack, square section,
Nylon



ZDB

Machined plastic
bevel gear (delrin),
2:1



SLHVlok

Toggle clamp,
Horizontal toggle
clamp / vertical foot

Complementary products



SDG

Guide support, Plastic



APB_BOU

Pin for clips, Safety
cap



SDG_SS

Guide support,
Stainless steel



APB_F

Rod for clamp,
Threaded