



- Flexible rack accessories

- Material:

Fixing rail: aluminium A6063S-T5


Clamps: SS400 unichromic plating

ARL

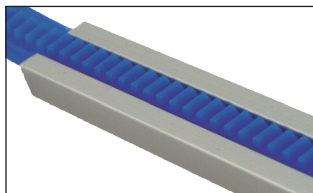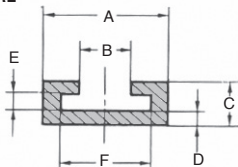

ARL rack fixing rail

SRS

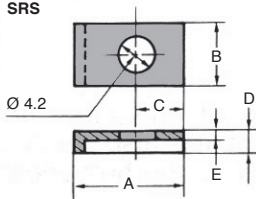

SRS rack clamp

DISCOUNTS

Qty	1+	3+	6+
Disc.	List	-10%	On request

Rack fixing rail

Part number	Length (mm)	A	B	C	D	E	F	Price each 1 to 2
ARL-0.8	1000	10,3	4,4	4,7	2,0	1,7	8,3	36,07 €
ARL-1	1000	12,3	5,6	5,2	2,0	2,2	10,3	41,32 €
ARL-1.5	1000	14,3	7,2	5,5	2,0	2,5	12,3	46,24 €
ARL-2	1000	17,3	8,8	6,2	2,5	2,7	15,3	61,28 €

Rack clamp

Part number	For rack	A	B	C	D	E	Qty per packet	Price per batch
SRS1/B	DR0.8-2000 and DR1-2000	10,2	8	4,5	2,7	1,2	10	18,34 €
SRS2/B	DR1.5-2000 and DR2-2000	11,4	8	5,6	3,9	1,4	10	18,34 €

Dimensions in mm

Our other products



CLB_M
Clamping lever -
female, Zamak



HLC19
Right angle bevel
gearbox, Up to 43Nm



CHAFR-MINI
Hinge, Miniature
friction hinge



DOMI80
DOMLINE -
Adjustment slide,
Slide DOMILINE 80
with counter and



TCL-ECL
Solid foot for heavy
loads, Fine thread



AT5M AT10M
Timing belt per metre,
AT10 Steel cored
polyurethane



CT
Universal joint,
telescopic, industrial



QTC
Clip on Quarter turn
latch, Slotted head



DKN
Bellows coupling
Gerwah®, from 0.4 to
10Nm



GAC
Latch clamp with lock,
Lockable




PHG15
Parallel axis helical
gear - Precision range,
20NCD2 case



NPTR10
Adjustable cross
clamp, Adjustable

Complementary products

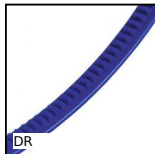

DR
Plastic flexible rack,
Rack



ARL_SRS
Plastic flexible rack,
Rack clamp