


- Accepts radial, axial and torque loads
- Maintenance free
- Materials:
Cylindrical body: steel
Insert: rubber NK50-60 Shore



Advantages

- A flexible bush is a superior replacement for a mechanical linkage where there is oscillation movement or a pivoting movement of limited amplitude

NEW!

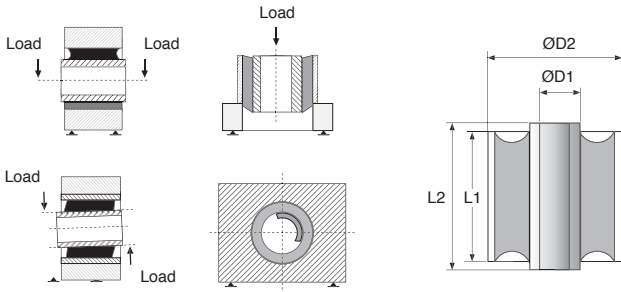

DISCOUNTS

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØD1	ØD2	L1	L2	Price each 1 to 5
ARTE8-16-17	8	16	15	17	9,16 €
ARTE8-16-28	8	16	25	28	10,72 €
ARTE8-20-17	8	20	15	17	9,42 €
ARTE8-22-16	8	22	10	16	10,52 €
ARTE10-18-20	10	18	18	20	11,46 €
ARTE10-20-24	10	20	20	24	21,79 €
ARTE10-22-17	10	22	15	17	9,51 €
ARTE10-22-30	10	22	25	30	10,23 €
ARTE10-24-17	10	24	14	17	11,95 €
ARTE10-25-24	10	25	20	24	12,18 €
ARTE10-27-51	10	27	45	51	12,18 €

Dimensions in mm

NEW!

DISCOUNTS

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØD1	ØD2	L1	L2	Price each 1 to 5
ARTE12-22-24	12	22	22	24	10,72 €
ARTE12-24-38	12	24	35	38	13,15 €
ARTE12-25-28	12	25	25	28	12,43 €
ARTE12-26-24	12	26	20	24	10,23 €
ARTE12-26-36	12	26	32	36	12,67 €
ARTE12-27-51	12	27	45	51	17,54 €
ARTE12-27-68	12	27	60	68	19,00 €
ARTE12-30-28	12	30	25	28	15,59 €
ARTE12-30-34	12	30	28	34	15,59 €
ARTE12-30-40	12	30	36	40	18,41 €
ARTE12-30-44	12	30	39	44	18,51 €
ARTE12-36-38	12	36	30	38	21,44 €
ARTE13-30-40	13	30	40	40	18,51 €
ARTE14-30-28	14	30	25	28	17,54 €
ARTE14-30-76	14	30	67	76	19,25 €
ARTE14-34-40	14	34	32	40	21,92 €
ARTE14-46-45	14	46	37	45	30,95 €
ARTE16-32-28	16	32	25	28	23,87 €
ARTE16-32-54	16	32	50	54	23,87 €
ARTE16-35-62	16	35	58	62	26,11 €
ARTE16-40-38	16	40	32	38	23,87 €
ARTE18-34-36	18	34	32	36	20,46 €
ARTE18-34-42	18	34	36	42	20,46 €
ARTE20-44-42	20	44	38	42	25,10 €
ARTE20-45-30	20	45	30	30	21,92 €
ARTE20-45-62	20	45	55	62	33,62 €
ARTE20-45-70	20	45	64	70	36,54 €
ARTE25-40-40	25	40	40	40	30,21 €
ARTE25-45-56	25	45	50	56	33,62 €
ARTE30-60-68	30	60	60	68	36,54 €
ARTE30-65-70	30	65	70	70	42,39 €
ARTE32-56-55	32	56	50	55	47,26 €
ARTE40-75-70	40	75	57	70	74,83 €
ARTE45-75-100	45	75	90	100	94,52 €
ARTE50-70-60	50	70	60	60	70,16 €
ARTE50-80-100	50	80	95	100	97,44 €

Dimensions in mm

Our other products



Sealed flange bearing unit for Food Industry, cover



Adjustable latch clamp with strike plate, Stroke from 174mm to 190mm



Screwed hinge with threaded insert, 138 degrees



Worm and wheel gear reducer, from 6.50 to 12.80 Nm



Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



Screwjack with travelling screw, with translating screw



Linear roller slide, Chariot - from 9410 N to 101000 N



Anti-vibration machine mount, Oval



Pull handle, Brass



Steel bevel gear, 2:1



Stainless steel bevel gear, 2:1

Complementary products