

# Welded lifting ring for straight lifts

## ASH

## Steel


- **Weldable lifting ring**
- Marked with CE symbol, CMU and manufacturer's ref
- **Material:**  
Black unfinished steel

### Assembly


- Installation instructions available on request
- Welding should be done in accordance with DIN 5817 (section 15 429) by an operator qualified to EN287-1

### Info.

- The breaking load is obtained by multiplying the SWL by a factor of safety of 5.

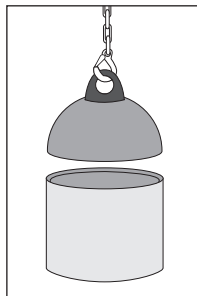

Typical application

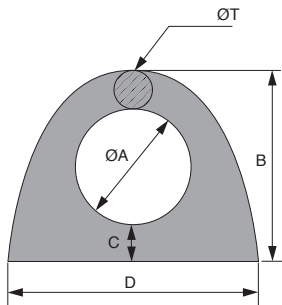


### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request

Part number	CMU (kg)	ØT	ØA	B	C	D	Weight (kg)	Stock*	Price each 1 to 5
ASH24-200	200	9	24	43	10	54	0,06	✓	2,22 €
ASH31-500	500	12	31	55	12	68	0,14	✓	3,18 €
ASH43-1000	1000	13	43	67	12	85	0,18	✓	4,77 €
ASH48-2000	2000	18	48	82	16	105	0,40	✓	7,41 €
ASH57-3000	3000	21	57	95	17	128	0,66	-	14,12 €
ASH67-4000	4000	25	67	107	15	148	1,02	-	26,87 €
ASH82-6000	6000	28	82	135	24	189	1,92	-	83,48 €
ASH100-8000	8000	30	100	165	35	210	3,12	-	87,69 €

Dimensions in mm

## Our other products

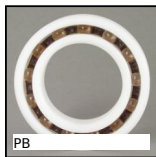

Plastic deep groove ball bearing, Plastic - glass balls material



Asynchronous AC motor 0.12 to 0.22kW, 0.12 to 0.22kW



Spring pin ISO8740, splined ISO 8740



Conveyor wheel, Plastic



Lock for aluminium profile, Lock for sliding doors



Spur gear coaxial gearbox, from 32 to 85 Nm - Inline



Female eye bolt conforms to DIN582, Stainless steel



Captive C washer, Slotted flat headed shoulder screw



Idle chain sprocket, For standard applications



Fixing support, Stainless steel



T-Clip - Aluminium profile attachment, Magnetic object



Cylindrical threaded sleeve, Cylindrical - steel

## Complementary products



Folding lifting ring for welding, Folding - for welding



Folding lifting ring for welding, Folding - for welding



45° Hoist ring for welding, for 45° lifts - for welding