

# Welded lifting ring for 45° lifts

Steel

ASL


- **Weldable lifting ring**
- Marked with CE symbol, CMU and manufacturer's ref
- Material:  
Black unfinished steel

## Assembly


- Installation instructions available on request
- Welding should be done in accordance with DIN 5817 (section 15 429) by an operator qualified to EN287-1

## Info.

- The breaking load is obtained by multiplying the SWL by a factor of safety of 5.

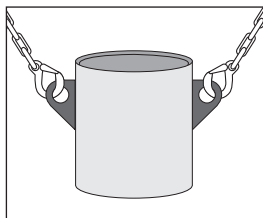

Typical application

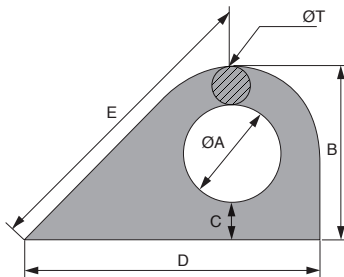

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request

Part number	CMU (kg)	ØT	ØA	B	C	D	E	Weight (kg)	Stock*	Price each 1 to 5
ASL31-500	500	12	31	55	13	89	82	0,16	✓	3,81 €
ASL42-1000	1000	14	42	69	13	113	101	0,30	✓	4,86 €
ASL45-2000	2000	18	45	81	18	134	123	0,50	✓	10,09 €
ASL57-3000	3000	21	57	97	19	152	140	0,80	-	16,92 €
ASL65-4000	4000	24	65	113	23	167	155	1,24	-	27,99 €
ASL83-6000	6000	28	83	140	31	218	205	2,36	-	70,16 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC** SUPPLEMENT 2019

225

## Our other products



ADL\_F

Female eye bolt conforms to DIN582, Stainless steel



MSP23

Masterplate® glueable insert Ø23, Cylindrical Ø23 with threaded s...



UCP\_SS

Stainless steel pillow block bearing, Stainless steel




CHM90

Worm and wheel gear reducer, up to 540 Nm



CHM50-MOT

 Asynchronous AC motorgearboxes 0.18 to 0.75kW, 0.18 to 0.75kW



PTA100

Articulated levelling foot, pressed base Ø100, Ø 100



WW10

Drylin® W slide, slide assembly



RBG

Wheel, Grey rubber - Polypropylene rim



HBM

Adjustment bushing for half-rail guide, Adjustment bushing



PCS37K

Chain sprocket with hardened teeth, 9.525mm (DIN06B-1)



PTA50ssEB

Articulated foot with sheet metal base Ø50, Articulated foot



ZG0

Plastic spur gear, Machined plastic (delrin)

## Complementary products



VLBS

Folding lifting ring for welding, Folding - for welding



VRBS

Folding lifting ring for welding, Folding - for welding



ASH

Hoist ring for welding, for straight lifts - for welding



VQT

Quarter-turn clamp lock, Plastic or stainless steel button