

# Welded lifting ring for 45° lifts

Steel

ASL

## - Weldable lifting ring


- Marked with CE symbol, CMU and manufacturer's ref
- Material:  
Black unfinished steel

## Assembly


- Installation instructions available on request
- Welding should be done in accordance with DIN 5817 (section 15 429) by an operator qualified to EN287-1

## Info.

- The breaking load is obtained by multiplying the SWL by a factor of safety of 5.

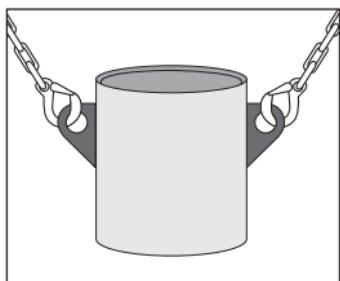

Typical application

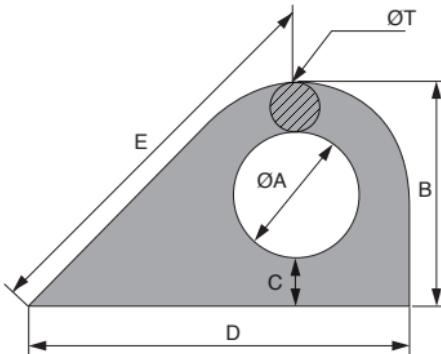

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List -10%	-20%	On request	

Part number	CMU (kg)	ØT	ØA	B	C	D	E	Weight (kg)	Stock*	Price each 1 to 5
ASL31-500	500	12	31	55	13	89	82	0,16	✓	3,81 €
ASL42-1000	1000	14	42	69	13	113	101	0,30	✓	4,86 €
ASL45-2000	2000	18	45	81	18	134	123	0,50	✓	10,09 €
ASL57-3000	3000	21	57	97	19	152	140	0,80	-	16,92 €
ASL65-4000	4000	24	65	113	23	167	155	1,24	-	27,99 €
ASL83-6000	6000	28	83	140	31	218	205	2,36	-	70,16 €

Dimensions in mm

Fax

0 825 88 6000

Service 0,15 € / min  
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

225

## Our other products



KK

Rounded end feather key, Steel



VP

Small 6 lobe threaded handle - male, Duroplast - Steel



SLB

Indexing plunger, stainless steel



AT5M AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane



G0

Steel spur gear, Steel 20NCD2



DOMI120

Accessories, Fixing kit



UCFL\_PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel



HLA19

Right angle spiro bevel gearbox, Up to 43Nm



TUBE25\_25

Square Tube, Aluminium or Stainless steel



GAC

Lock for latch clamp, Strike plate



VRC2

Retaining clamp, dual sided, Dual sided



BOX-TOR-D

Box set of Nitrile O-rings in nitrile, 18.00 x 2.00mm to 50.00 x 5.00

## Complementary products



VLBS

Folding lifting ring for welding, Folding - for welding



VRBS

Folding lifting ring for welding, Folding - for welding



ASH

Hoist ring for welding, for straight lifts - for welding