

Welded lifting ring for 45° lifts

Steel

ASL


- **Weldable lifting ring**
- Marked with CE symbol, CMU and manufacturer's ref
- Material:
Black unfinished steel

Assembly


- Installation instructions available on request
- Welding should be done in accordance with DIN 5817 (section 15 429) by an operator qualified to EN287-1

Info.

- The breaking load is obtained by multiplying the SWL by a factor of safety of 5.

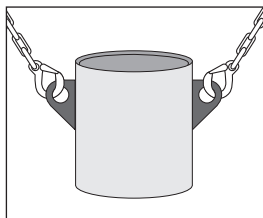

Typical application

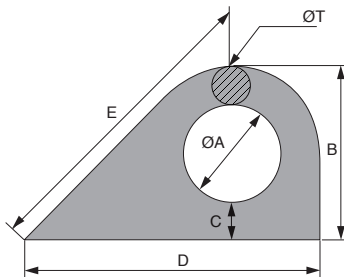

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request

Part number	CMU (kg)	ØT	ØA	B	C	D	E	Weight (kg)	Stock*	Price each 1 to 5
ASL31-500	500	12	31	55	13	89	82	0,16	✓	3,81 €
ASL42-1000	1000	14	42	69	13	113	101	0,30	✓	4,86 €
ASL45-2000	2000	18	45	81	18	134	123	0,50	✓	10,09 €
ASL57-3000	3000	21	57	97	19	152	140	0,80	-	16,92 €
ASL65-4000	4000	24	65	113	23	167	155	1,24	-	27,99 €
ASL83-6000	6000	28	83	140	31	218	205	2,36	-	70,16 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC SUPPLEMENT 2019

225

Our other products



SSDB

Stainless steel bevel gear, 2:1



AT5-16ECO

Synchronous pulley, Economy range - AT5 aluminium



 
H2

90° crossed axis helical gear, Machined plastic (delrin)



MATCD

Ground precision shaft, Pre-hardened steel (42CD4T) bar



RFVbr

Stainless steel gearbox - accessories, Reaction arm



QUK

Freewheel, With internal bearing



MFB-MHB-ALI

Moulded plastic bevel gear (blue nylon), 1.5:1



FIRSTDC1Q60

Servo amplifier, 10 A



CHM75

Worm and wheel gearbox, up to 298 Nm



ACA

Splined shaft, Steel



CHM110

Worm and wheel gearbox, up to 980 Nm



SLB

Indexing plunger, stainless steel

Complementary products



VLBS

Lifting ring, Folding - for welding



VRBS

Lifting ring, Folding - for welding



ASH

Hoist ring, for straight lifts - for welding