

Aluminium

Pitch
AT10

For 25mm belts





- For use with AT10 belts
- Pitch 10mm
- Material:
Aluminium

Accessories

- AT10 belts
- GTC tension rollers

Info

- *Pilot bore given as indication, may vary between batches.
- Will require re-machining by customer
- **We are unable to modify this product**

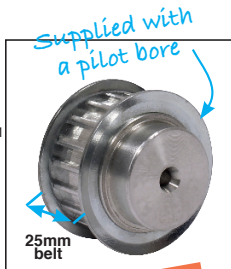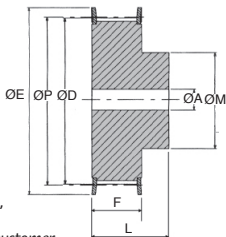

Economy range

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	ØP PDC	ØD external	ØE flange	ØM	F	L	Pilot bore		Price each 1 to 5
								not guaranteed	ØA*	
15AT10-25/ECO	15	47,75	45,90	51	32	30	40	8		10,52 €
16AT10-25/ECO	16	50,93	49,05	54	35	30	40	8		11,78 €
18AT10-25/ECO	18	57,29	55,45	60	40	30	40	8		14,08 €
19AT10-25/ECO	19	60,48	58,60	66,5	44	30	40	8		15,75 €
20AT10-25/ECO	20	63,66	61,80	66,5	46	30	40	8		16,88 €
22AT10-25/ECO	22	70,03	68,15	75	52	30	40	8		21,12 €
24AT10-25/ECO	24	76,39	74,55	83	58	30	40	8		23,74 €
25AT10-25/ECO	25	79,58	77,70	83	60	30	40	8		23,98 €
26AT10-25/ECO	26	82,76	80,90	87	60	30	40	8		26,60 €
27AT10-25/ECO	27	85,95	84,10	91	60	30	40	8		29,29 €
28AT10-25/ECO	28	89,12	87,25	93	60	30	40	8		29,35 €
30AT10-25/ECO	30	95,49	93,65	102	60	30	40	8		35,19 €
32AT10-25/ECO	32	101,86	100,00	106	65	30	40	10		38,22 €
36AT10-25/ECO	36	114,59	112,75	119	70	30	40	10		45,18 €
40AT10-25/ECO	40	127,32	125,45	131	80	30	40	10		56,20 €
44AT10-25/ECO	44	140,05	138,20	-	88	30	40	10		71,51 €
48AT10-25/ECO	48	152,78	150,95	-	95	30	40	16		76,80 €
60AT10-25/ECO	60	190,98	189,10	-	110	30	40	16		126,64 €

Dimensions in mm

Our other products




PAMF80EB
Articulated foot with sheet metal base Ø80, Articulated foot



OPFL_OPPM
Numerical counter accessories, Locking clamp



BCTH
Mushroom headed button Hygienic Usit®, With female thread and high ...

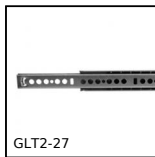

GLT2-27
Telescopic drawer runners for groove mounting, Partial extension



ERF
Quick fitting threaded cable terminal, Cable terminal with threaded ...



SBF
Sealed flange bearing unit for Food Industry, cover



PRES7HR
Manual workbench press, Force up to 700kg



HTD14M_85
HTD Heavy duty timing pulley, HTD14 Steel



T5M_T10M
T type timing belt per metre, T5 Steel cored polyurethane



PPG
Indexing plunger with flange, With horizontal mounting



NT63
Spur gear coaxial gearbox, from 8 to 20 Nm - In-line



PLM-SC
Magnetic stud with threaded hole, With threaded hole

Complementary products



GTC
Belt tensioner, For standard applications



AT10courroie
AT type timing belt, AT10 Steel cored polyurethane



AT10-BAR
AT type tooth bar stock, AT10



AT5M_AT10M
AT type timing belt per metre, AT10 Steel cored polyurethane