

# AT-type timing pulley

Aluminium

Pitch  
**AT10**

For 25mm belts





- For use with AT10 belts
- Pitch 10mm
- Material:  
Aluminium

## Accessories

- AT10 belts
- GTC tension rollers

## Info

- \*Pilot bore given as indication, may vary between batches.
- Will require re-machining by customer
- **We are unable to modify this product**

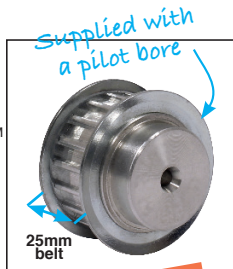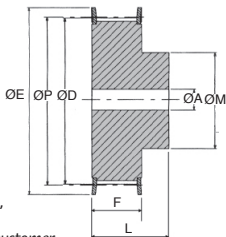

**Economy range**

## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	ØP PDC	ØD external	ØE flange	ØM	F	L	Pilot bore		Price each 1 to 5
								not guaranteed	ØA*	
15AT10-25/ECO	15	47,75	45,90	51	32	30	40	8		10,52 €
16AT10-25/ECO	16	50,93	49,05	54	35	30	40	8		11,78 €
18AT10-25/ECO	18	57,29	55,45	60	40	30	40	8		14,08 €
19AT10-25/ECO	19	60,48	58,60	66,5	44	30	40	8		15,75 €
20AT10-25/ECO	20	63,66	61,80	66,5	46	30	40	8		16,88 €
22AT10-25/ECO	22	70,03	68,15	75	52	30	40	8		21,12 €
24AT10-25/ECO	24	76,39	74,55	83	58	30	40	8		23,74 €
25AT10-25/ECO	25	79,58	77,70	83	60	30	40	8		23,98 €
26AT10-25/ECO	26	82,76	80,90	87	60	30	40	8		26,60 €
27AT10-25/ECO	27	85,95	84,10	91	60	30	40	8		29,29 €
28AT10-25/ECO	28	89,12	87,25	93	60	30	40	8		29,35 €
30AT10-25/ECO	30	95,49	93,65	102	60	30	40	8		35,19 €
32AT10-25/ECO	32	101,86	100,00	106	65	30	40	10		38,22 €
36AT10-25/ECO	36	114,59	112,75	119	70	30	40	10		45,18 €
40AT10-25/ECO	40	127,32	125,45	131	80	30	40	10		56,20 €
44AT10-25/ECO	44	140,05	138,20	-	88	30	40	10		71,51 €
48AT10-25/ECO	48	152,78	150,95	-	95	30	40	16		76,80 €
60AT10-25/ECO	60	190,98	189,10	-	110	30	40	16		126,64 €

Dimensions in mm


## Our other products




PLM-C  
Flat gripping magnet,  
Flat holding magnet



P60  
Worm and wheel gear  
reducer, up to 118  
Nm

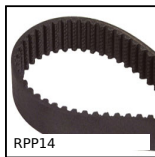

RPP14  
RPP heavy duty  
timing belt, RPP14

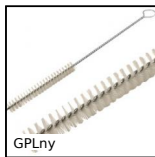

GPLny  
Brush, nylon



PRF1932  
Standard aluminium  
profile, 19 x 32 mm



PRF\_FIX\_STD  
Fastener for  
aluminium profile,  
Standard fastener



VRM  
Female swivelling  
lifting rings, Female  
swivelling



AT5P\_AT10P  
Connecting plate for  
AT type timing belts,  
AT5



EMS  
Stainless steel knurled  
thumb nut, Knurled



ZDB  
Machined plastic  
bevel gear , 2:1



VAP  
Magnetic stud with  
central hole, With  
central hole



AFM  
Flanged polymer  
bush, Food grade  
polymer

## Complementary products



GTC  
Belt tensioner, For  
standard applications



AT10courroie  
AT type timing belt,  
AT10 Steel cored  
polyurethane



AT10-BAR  
AT type tooth bar  
stock, AT10



AT5M AT10M  
AT type timing belt  
per metre, AT10 Steel  
cored polyurethane