

# AT-type timing pulley



## Pitch AT10

## Aluminium

For 32mm belts


- For use with AT10 belts
- Pitch 10mm
- Material:  
Aluminium

### Accessories

- AT10 belts
- GTC tension rollers

### Info

- \*Pilot bore given as indication,  
may vary between batches.
- Will require re-machining by customer
- We are unable to modify this product

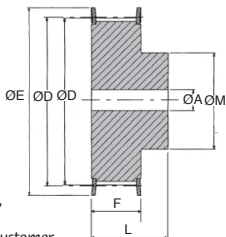

**Economy range**

### DISCOUNTS

| Qty   | 1+        | 6+         | 20+ |
|-------|-----------|------------|-----|
| Disc. | List -12% | On request |     |

| Part number   | No of teeth | Ø PCD  | ØD external | ØE flange | ØM  | F  | L  | Pilot bore not guaranteed<br>ØA* | Price each 1 to 5 |
|---------------|-------------|--------|-------------|-----------|-----|----|----|----------------------------------|-------------------|
| 18AT10-32/ECO | 18          | 57,29  | 55,45       | 60        | 40  | 37 | 47 | 10                               | 15,75 €           |
| 19AT10-32/ECO | 19          | 60,48  | 58,60       | 66,5      | 44  | 37 | 47 | 10                               | 17,58 €           |
| 20AT10-32/ECO | 20          | 63,66  | 61,80       | 66,5      | 46  | 37 | 47 | 12                               | 18,92 €           |
| 22AT10-32/ECO | 22          | 70,03  | 68,15       | 75        | 52  | 37 | 47 | 12                               | 23,74 €           |
| 24AT10-32/ECO | 24          | 76,39  | 74,55       | 83        | 58  | 37 | 47 | 12                               | 26,72 €           |
| 25AT10-32/ECO | 25          | 79,58  | 77,70       | 83        | 60  | 37 | 47 | 12                               | 26,95 €           |
| 26AT10-32/ECO | 26          | 82,76  | 80,90       | 87        | 60  | 37 | 47 | 12                               | 29,99 €           |
| 27AT10-32/ECO | 27          | 85,95  | 84,10       | 91        | 60  | 37 | 47 | 12                               | 33,12 €           |
| 28AT10-32/ECO | 28          | 89,12  | 87,25       | 93        | 60  | 37 | 47 | 12                               | 33,22 €           |
| 30AT10-32/ECO | 30          | 95,49  | 93,65       | 102       | 60  | 37 | 47 | 12                               | 39,67 €           |
| 32AT10-32/ECO | 32          | 101,86 | 100,00      | 106       | 65  | 37 | 47 | 12                               | 43,64 €           |
| 36AT10-32/ECO | 36          | 114,59 | 112,75      | 119       | 70  | 37 | 47 | 16                               | 51,54 €           |
| 40AT10-32/ECO | 40          | 127,32 | 125,45      | 131       | 80  | 37 | 47 | 16                               | 64,47 €           |
| 44AT10-32/ECO | 44          | 140,05 | 138,20      | -         | 88  | 37 | 47 | 16                               | 82,03 €           |
| 48AT10-32/ECO | 48          | 152,78 | 150,95      | -         | 95  | 37 | 47 | 16                               | 88,25 €           |
| 60AT10-32/ECO | 60          | 190,98 | 189,10      | -         | 110 | 37 | 47 | 16                               | 144,86 €          |

Dimensions in mm

## Our other products



SRG

Adjustable latch clamp with strike plate, Stroke from 78mm to 90mm



EHD12

Internal epicyclic servo reducers, from 60 to 140 Nm



NCT\_AT

Variable angle connector, Variable angle



PTAF100-PAMF100

Articulated fixable foot with pressed base  $\varnothing 100$ ,  $\varnothing 100$



VTA

Vari-Tork® slip friction clutch, 0.53 to 1.32 Nm



BDM

Pin for magnetic bush, Fast and light magnetic locking



HTD8M\_30

HTD Heavy duty timing pulley, HTD8 Cast



CHB

Double output shaft, For CHB gearbox



CHTRB

Single and dual output gearboxes, Up



PSG05

Spur gear - precision range, Case hardened



HG6

Steel spur gear, Steel 20NCD2



LVT

Miniature motorised actuator 4A, 4 amperes

## Complementary products



GTC

Belt tensioner, For standard applications



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane



AT10-BAR

AT type tooth bar stock, AT10



AT5M AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane