

AT-type timing pulley



Pitch AT10

Aluminium

For 32mm belts


- For use with AT10 belts
- Pitch 10mm
- Material:
Aluminium

Accessories

- AT10 belts
- GTC tension rollers

Info

- *Pilot bore given as indication,
may vary between batches.
- Will require re-machining by customer
- We are unable to modify this product

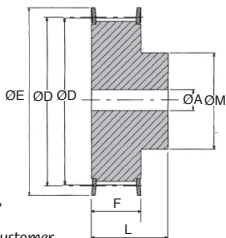

Economy range

DISCOUNTS

Qty	1+	6+	20+
Disc.	List -12%	On request	

Part number	No of teeth	Ø PCD	ØD external	ØE flange	ØM	F	L	Pilot bore not guaranteed ØA*	Price each 1 to 5
18AT10-32/ECO	18	57,29	55,45	60	40	37	47	10	15,75 €
19AT10-32/ECO	19	60,48	58,60	66,5	44	37	47	10	17,58 €
20AT10-32/ECO	20	63,66	61,80	66,5	46	37	47	12	18,92 €
22AT10-32/ECO	22	70,03	68,15	75	52	37	47	12	23,74 €
24AT10-32/ECO	24	76,39	74,55	83	58	37	47	12	26,72 €
25AT10-32/ECO	25	79,58	77,70	83	60	37	47	12	26,95 €
26AT10-32/ECO	26	82,76	80,90	87	60	37	47	12	29,99 €
27AT10-32/ECO	27	85,95	84,10	91	60	37	47	12	33,12 €
28AT10-32/ECO	28	89,12	87,25	93	60	37	47	12	33,22 €
30AT10-32/ECO	30	95,49	93,65	102	60	37	47	12	39,67 €
32AT10-32/ECO	32	101,86	100,00	106	65	37	47	12	43,64 €
36AT10-32/ECO	36	114,59	112,75	119	70	37	47	16	51,54 €
40AT10-32/ECO	40	127,32	125,45	131	80	37	47	16	64,47 €
44AT10-32/ECO	44	140,05	138,20	-	88	37	47	16	82,03 €
48AT10-32/ECO	48	152,78	150,95	-	95	37	47	16	88,25 €
60AT10-32/ECO	60	190,98	189,10	-	110	37	47	16	144,86 €

Dimensions in mm

Our other products



gt64r

Rotating bent lever with spring, increased fitting tolerances



SUPccss

Self-centering clamping hub stainless steel, With lock nut



PTRSS

Idle chain sprocket, For hostile environments



SLV

Vertical toggle clamp, Vertical Lever Clamp - steel



PR65C

Half-articulated foot Ø 65, Ø 65



PITA

Locking bolt, with T handle



CHTRP

Single and dual output gearboxes, Up to 75,7 Nm



CHML40

Worm and wheel gear reducer, up to 57 Nm - Integrated torque limiter



DSF

Slip friction clutch, 4 to 2600 Nm



NSU

Universal 90° support clamp, Universal 90° support clamp



PSG125S

Spur gear - precision range, Stainless steel 316



CHAEpac

Square decorative screwed hinges, carbon fibre reinforced

Complementary products



GTC

Belt tensioner, For standard applications



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane



AT10-BAR

AT type tooth bar stock, AT10



AT5M AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane