

AT-type timing pulley



Pitch AT10

Aluminium

For 32mm belts


- For use with AT10 belts
- Pitch 10mm
- Material:
Aluminium

Accessories

- AT10 belts
- GTC tension rollers

Info

- *Pilot bore given as indication,
may vary between batches.
- Will require re-machining by customer
- We are unable to modify this product

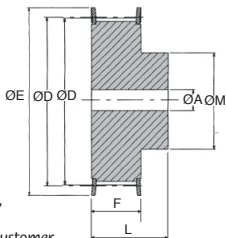

Economy range

DISCOUNTS

Qty	1+	6+	20+
Disc.	List -12%	On request	

Part number	No of teeth	Ø PCD	ØD external	ØE flange	ØM	F	L	Pilot bore not guaranteed ØA*	Price each 1 to 5
18AT10-32/ECO	18	57,29	55,45	60	40	37	47	10	15,75 €
19AT10-32/ECO	19	60,48	58,60	66,5	44	37	47	10	17,58 €
20AT10-32/ECO	20	63,66	61,80	66,5	46	37	47	12	18,92 €
22AT10-32/ECO	22	70,03	68,15	75	52	37	47	12	23,74 €
24AT10-32/ECO	24	76,39	74,55	83	58	37	47	12	26,72 €
25AT10-32/ECO	25	79,58	77,70	83	60	37	47	12	26,95 €
26AT10-32/ECO	26	82,76	80,90	87	60	37	47	12	29,99 €
27AT10-32/ECO	27	85,95	84,10	91	60	37	47	12	33,12 €
28AT10-32/ECO	28	89,12	87,25	93	60	37	47	12	33,22 €
30AT10-32/ECO	30	95,49	93,65	102	60	37	47	12	39,67 €
32AT10-32/ECO	32	101,86	100,00	106	65	37	47	12	43,64 €
36AT10-32/ECO	36	114,59	112,75	119	70	37	47	16	51,54 €
40AT10-32/ECO	40	127,32	125,45	131	80	37	47	16	64,47 €
44AT10-32/ECO	44	140,05	138,20	-	88	37	47	16	82,03 €
48AT10-32/ECO	48	152,78	150,95	-	95	37	47	16	88,25 €
60AT10-32/ECO	60	190,98	189,10	-	110	37	47	16	144,86 €

Dimensions in mm

Our other products



MAX26

Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm



 
ASM

Cylindrical polymer bush, Food grade polymer




ACA

Steel splined shaft, Steel



LRH

 Bi-directional leadscrew, Bi-directional - 1 thread



QN

Single row cylindrical roller bearing, Free outer ring



GBSz

Cylindrical ballscrew nut, Cylindrical leadscrew nut



F7-SF-SM

Multifunction display, Right angled mounting bracket



G-ECO

Eco range Spur gear, Steel C45



BPHFclip

Clip for ball transfer unit, Insert clip - Installing from above



LWH

High rigidity linear slide, Rail - from 9320 N to 71300 N



GLB

Small 6 lobe threaded handle - female, Technopolymer - Brass



BOX-TOR-MAX

Box set of Nitrile O-rings in nitrile, 2.90 x 1.78mm to 82.14 x 3.53

Complementary products



GTC

Belt tensioner, For standard applications



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane



AT10-BAR

AT type tooth bar stock, AT10



AT5M AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane