





- For use with AT10 belts
- Pitch 10mm
- Material:
Aluminium

Accessories

- AT10 belts
- GTC tension rollers

Info

- *Pilot bore given as indication, may vary between batches.
- Will require re-machining by customer
- We are unable to modify this product

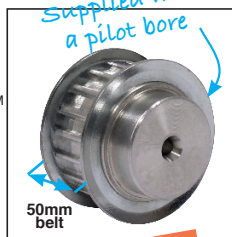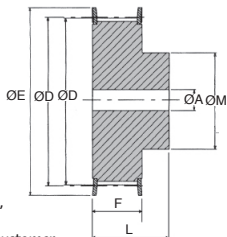

Economy range

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	Ø PCD	ØD external	ØE flange	ØM	F	L	Pilot bore	Price each
								not guaranteed	
18AT10-50/ECO	18	57,29	55,45	60	40	56	66	10	20,66 €
19AT10-50/ECO	19	60,48	58,60	66,5	44	56	66	10	23,13 €
20AT10-50/ECO	20	63,66	61,80	66,5	46	56	66	12	24,90 €
22AT10-50/ECO	22	70,03	68,15	75	52	56	66	12	31,59 €
24AT10-50/ECO	24	76,39	74,55	83	58	56	66	12	35,60 €
25AT10-50/ECO	25	79,58	77,70	83	60	56	66	12	35,94 €
26AT10-50/ECO	26	82,76	80,90	87	60	56	66	12	39,98 €
27AT10-50/ECO	27	85,95	84,10	91	60	56	66	12	44,02 €
28AT10-50/ECO	28	89,12	87,25	93	60	56	66	12	44,33 €
30AT10-50/ECO	30	95,49	93,65	102	60	56	66	12	52,98 €
32AT10-50/ECO	32	101,86	100,00	106	65	56	66	12	58,36 €
36AT10-50/ECO	36	114,59	112,75	119	70	56	66	16	69,14 €
40AT10-50/ECO	40	127,32	125,45	131	80	56	66	16	86,38 €
44AT10-50/ECO	44	140,05	138,20	-	88	56	66	16	110,56 €
48AT10-50/ECO	48	152,78	150,95	-	95	56	66	16	119,08 €
60AT10-50/ECO	60	190,98	189,10	-	110	56	66	16	194,88 €

Dimensions in mm

Our other products



EHD06

Internal epicyclic servo reducers, from 8 to 19 Nm



RBNpl

Fixed castor with plate, Steel - rubber



GMC_GMK_BR

Guiding profile clamp, Flat or rounded



RESC

Retractable castor for aluminium profile, Retractable castor




PRT-TO

iglidur® slewing ring, With external teeth-Iglidur®, aluminium & S...




DOMI120

 Accessories, Plate



HLUss

 Spoked handwheel, Stainless steel 316



PB

Plastic deep groove ball bearing, Plastic - balls material : staine...



SHSS

Shoulder screw stainless steel 416, Pre-treated 416 stainless steel



CHAu

Screwed hinge, 270°



MFB

Flexible bellows coupling, Aluminium and Bronze - With set screw



ACL-PL

Joining plate for aluminium profile, Joint plate - 86x86 mm

Complementary products



GTC

Belt tensioner, For standard applications



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane



AT10-BAR

AT type tooth bar stock, AT10



AT5M AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane