 



- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Aluminium suitable for hard anodic oxidation
- Finish : Supplied not-treated



Info.

- We are unable to modify this product

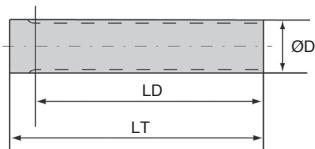

DISCOUNTS

Qty	1+	2+	4+
Disc. List	-20%	-20%	On request

Part number	Z Teeth	ØD External	Length of teeth L _D	Total length L _T	Price each
15AT10-BAR	15	45,90	160	160	30,93 €
16AT10-BAR	16	49,14	160	160	35,15 €
18AT10-BAR	18	55,45	160	160	42,21 €
19AT10-BAR	19	58,65	160	160	47,31 €
20AT10-BAR	20	61,80	160	160	51,41 €
21AT10-BAR	21	65,00	160	160	55,66 €
22AT10-BAR	22	68,20	160	160	65,98 €
23AT10-BAR	23	71,35	160	160	66,28 €
24AT10-BAR	24	74,55	160	160	74,32 €
25AT10-BAR	25	77,75	160	160	74,88 €
26AT10-BAR	26	80,90	160	160	83,42 €
28AT10-BAR	28	87,25	160	160	92,83 €
30AT10-BAR	30	93,65	160	160	112,55 €
32AT10-BAR	32	100,00	160	160	123,56 €
34AT10-BAR	34	106,40	160	160	135,20 €
36AT10-BAR	36	112,75	160	160	148,54 €
38AT10-BAR	38	119,10	160	160	172,13 €
40AT10-BAR	40	125,45	160	160	185,77 €
42AT10-BAR	42	131,85	160	160	210,24 €
44AT10-BAR	44	138,20	160	160	230,17 €
46AT10-BAR	46	144,55	160	160	247,96 €
48AT10-BAR	48	150,95	160	160	262,35 €
52AT10-BAR	52	163,65	160	160	317,75 €
56AT10-BAR	56	176,40	160	160	365,45 €
60AT10-BAR	60	189,15	160	160	432,22 €

Dimensions in mm

Our other products



BDPR

Holding arm, Rigid



AT5courroie

AT type timing belt,
AT5 Steel cored
polyurethane



CHTRP

Single and dual
output gearboxes, Up
to 87,3Nm



SH0

Parallel axis helical
gear, Steel 20NCD2



MBF

Threaded blocking
clamp, Threaded
locking clamp



PRF_CLIP_22

Cable clip for
aluminium profile, For
electric and
pneumatic cables



FBL6000_K13

Brush strip per meter
PP fibres Ø0.2, Black
striated polypropylene
...



MSP19

Masterplate®
glueable insert
Ø19/Ø20, Cylindrical
with nut



PRES2HR

Manual workbench
press, Force up to
200kg



CAP815

Slim slat top chain
stainless steel,
Narrow range 815



AT10-50ECO

AT type timing pulley,
Economy range -
AT10 aluminium



CHTRP

Single and dual
output gearboxes, Up
to 9,1 Nm

Complementary products



AT5-BAR

AT type tooth bar
stock, AT5



AT10-25ECO

AT type timing pulley,
Economy range -
AT10 aluminium



AT10-32ECO

AT type timing pulley,
Economy range -
AT10 aluminium



AT10-50ECO

AT type timing pulley,
Economy range -
AT10 aluminium