

# AT-type timing pulley



## Pitch AT5

## Aluminium



For 10mm belts



- For use with AT5 belts
- Pitch 5mm
- Material:  
Aluminium

### Accessories

- AT5 belts
- GTC tension rollers

### Info

- \*Pilot bore size given as a indication, may vary between batches
- Will require re-machining by customer
- **We are unable to modify this product**

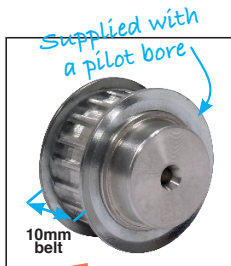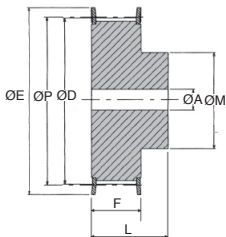

**Economy range**

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	ØP PCD	ØD external	ØE flange	ØM	F	L	Pilot bore not guaranteed	
								ØA*	Price each 1 to 5
12AT5-10/ECO	12	19,10	17,85	23	11	15	21	-	2,95 €
14AT5-10/ECO	14	22,29	21,05	25	13	15	21	-	3,24 €
15AT5-10/ECO	15	23,88	22,65	28	16	15	21	6	3,47 €
16AT5-10/ECO	16	25,47	24,20	32	18	15	21	6	3,84 €
18AT5-10/ECO	18	28,65	27,40	32	20	15	21	6	4,06 €
19AT5-10/ECO	19	30,25	29,00	36	22	15	21	6	4,49 €
20AT5-10/ECO	20	31,83	30,60	36	23	15	21	6	4,74 €
22AT5-10/ECO	22	35,02	33,85	38	24	15	21	6	5,38 €
24AT5-10/ECO	24	38,21	37,00	42	26	15	21	6	5,76 €
25AT5-10/ECO	25	39,80	38,60	44	26	15	21	6	6,13 €
26AT5-10/ECO	26	41,39	40,20	44	26	15	21	6	6,66 €
27AT5-10/ECO	27	42,98	41,80	48	30	15	21	8	6,88 €
28AT5-10/ECO	28	44,58	43,35	48	32	15	21	8	7,34 €
30AT5-10/ECO	30	47,76	46,55	51	34	15	21	8	7,85 €
32AT5-10/ECO	32	50,94	49,70	54	38	15	21	8	8,84 €
36AT5-10/ECO	36	57,31	56,05	64	38	15	21	8	10,24 €
40AT5-10/ECO	40	63,66	62,45	66,5	40	15	21	8	11,63 €
42AT5-10/ECO	42	66,86	65,60	70	40	15	21	8	12,54 €
44AT5-10/ECO	44	70,05	68,80	-	45	15	21	8	12,58 €
48AT5-10/ECO	48	76,42	75,15	-	50	15	21	8	14,16 €
60AT5-10/ECO	60	95,52	94,25	-	65	15	21	8	21,12 €

Dimensions in mm

## Our other products



UTKpwc

Utilitrak® 3 wheels carriage, Polymer series V wheels



HTD5M\_09

HTD Heavy duty timing pulley, HTD5 Aluminium



ZBconique

Machined plastic bevel gear, 1:1



BLHB50

Right angled gearbox, bored shafts, up to 30 Nm



CAP805

Slat top chain stainless steel, Large range 805



ATZYSS

Stainless steel diablo shaped elasto mount, Stainless steel



SLH-M

Nut for toggle clamp, Round ended nut for SLH/SLV clamp



BAN

Angular clamp, Universal



NT62

Spur gear coaxial gearbox, from 6 to 18



SLVlok

Vertical toggle clamp, Vertical toggle clamp /



INS

Self tapping steel insert, Steel



BABV

Ball lock pins lockable, Stainless steel

## Complementary products



GTC

Belt tensioner, For standard applications



AT5courroie

AT type timing belt, AT5 Steel cored polyurethane



AT5-BAR

AT type tooth bar stock, AT5



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane