

AT-type timing pulley



Pitch AT5

For 10mm belts

- For use with AT5 belts
- Pitch 5mm
- Material:
Aluminium



Accessories

- AT5 belts
- GTC tension rollers

Info

- *Pilot bore size given as a indication, may vary between batches
- Will require re-machining by customer
- **We are unable to modify this product**

Aluminium

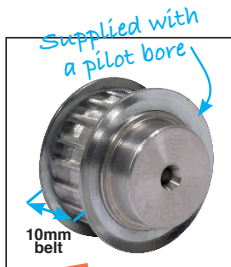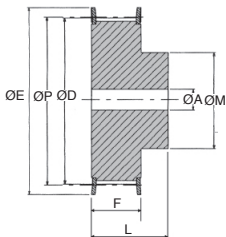

Economy range

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	ØP PCD	ØD external	ØE flange	ØM	F	L	Pilot bore not guaranteed	
								ØA*	Price each 1 to 5
12AT5-10/ECO	12	19,10	17,85	23	11	15	21	-	2,95 €
14AT5-10/ECO	14	22,29	21,05	25	13	15	21	-	3,24 €
15AT5-10/ECO	15	23,88	22,65	28	16	15	21	6	3,47 €
16AT5-10/ECO	16	25,47	24,20	32	18	15	21	6	3,84 €
18AT5-10/ECO	18	28,65	27,40	32	20	15	21	6	4,06 €
19AT5-10/ECO	19	30,25	29,00	36	22	15	21	6	4,49 €
20AT5-10/ECO	20	31,83	30,60	36	23	15	21	6	4,74 €
22AT5-10/ECO	22	35,02	33,85	38	24	15	21	6	5,38 €
24AT5-10/ECO	24	38,21	37,00	42	26	15	21	6	5,76 €
25AT5-10/ECO	25	39,80	38,60	44	26	15	21	6	6,13 €
26AT5-10/ECO	26	41,39	40,20	44	26	15	21	6	6,66 €
27AT5-10/ECO	27	42,98	41,80	48	30	15	21	8	6,88 €
28AT5-10/ECO	28	44,58	43,35	48	32	15	21	8	7,34 €
30AT5-10/ECO	30	47,76	46,55	51	34	15	21	8	7,85 €
32AT5-10/ECO	32	50,94	49,70	54	38	15	21	8	8,84 €
36AT5-10/ECO	36	57,31	56,05	64	38	15	21	8	10,24 €
40AT5-10/ECO	40	63,66	62,45	66,5	40	15	21	8	11,63 €
42AT5-10/ECO	42	66,86	65,60	70	40	15	21	8	12,54 €
44AT5-10/ECO	44	70,05	68,80	-	45	15	21	8	12,58 €
48AT5-10/ECO	48	76,42	75,15	-	50	15	21	8	14,16 €
60AT5-10/ECO	60	95,52	94,25	-	65	15	21	8	21,12 €

Dimensions in mm

Our other products



RFK28B

Hypoid gearbox -
Stainless steel, up to
130 Nm



AT5-16ECO

AT type timing pulley,
Economy range - AT5
aluminium




SC2

2 part rigid shaft
clamp, Clamping jaw



SSDB

 Stainless steel bevel
gear, 2:1



QN

Single row cylindrical
roller bearing, Free
outer ring



NT61

Spur gear coaxial
gearbox, from 5 to 14
Nm - In-line



AC

Strike for toggle latch,
12mm



PRF_PGN

Door handle for
aluminium profile,
Handle with lock
suitable



PRF_FIX_STD

Fastener for
aluminium profile,



HSE-HSB

Hexagonal spacer,
Brass



PRF-SCREEN-5

Screen support,
Support with 5 axes of



EMS

Stainless steel knurled
thumb nut, Knurled

Complementary products



GTC

Belt tensioner, For
standard applications



AT5courroie

AT type timing belt,
AT5 Steel cored
polyurethane



AT5-BAR

AT type tooth bar
stock, AT5



AT5M AT10M

AT type timing belt
per metre, AT5 Steel
cored polyurethane