

## Aluminium

## Pitch AT5



For 16mm belts



- For use with AT5 belts
- Pitch 5mm
- Material: Aluminium

### Accessories

- AT5 belts
- GTC tension rollers

### Info

- \*Pilot bore size given as a indication, may vary between batches.
- Will require re-machining by customer
- **We are unable to modify this product**

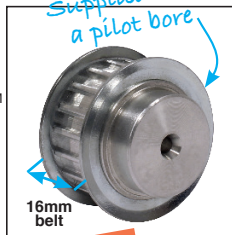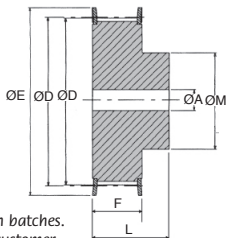

**Economy range**

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	Ø PDC	ØD external	ØE flange	ØM	F	L	Pilot bore not guaranteed	
								ØA*	Price each 1 to 5
12AT5-16/ECO	12	19,10	17,85	23	11	21	27	-	3,38 €
14AT5-16/ECO	14	22,29	21,05	25	13	21	27	-	3,70 €
15AT5-16/ECO	15	23,88	22,65	28	16	21	27	6	4,06 €
16AT5-16/ECO	16	25,47	24,20	32	18	21	27	6	4,41 €
18AT5-16/ECO	18	28,65	27,40	32	20	21	27	6	4,74 €
19AT5-16/ECO	19	30,25	29,00	36	22	21	27	6	5,24 €
20AT5-16/ECO	20	31,83	30,60	36	23	21	27	6	5,48 €
22AT5-16/ECO	22	35,02	33,85	38	24	21	27	6	6,31 €
24AT5-16/ECO	24	38,21	37,00	42	26	21	27	6	6,80 €
25AT5-16/ECO	25	39,80	38,60	44	26	21	27	6	7,21 €
26AT5-16/ECO	26	41,39	40,20	44	26	21	27	6	7,85 €
27AT5-16/ECO	27	42,98	41,80	48	30	21	27	8	7,95 €
28AT5-16/ECO	28	44,58	43,35	48	32	21	27	8	8,71 €
30AT5-16/ECO	30	47,76	46,55	51	34	21	27	8	9,25 €
32AT5-16/ECO	32	50,94	49,70	54	38	21	27	8	10,43 €
36AT5-16/ECO	36	57,31	56,05	64	38	21	27	8	12,29 €
40AT5-16/ECO	40	63,66	62,45	66,5	40	21	27	8	13,83 €
42AT5-16/ECO	42	66,86	65,60	70	40	21	27	8	14,87 €
44AT5-16/ECO	44	70,05	68,80	-	45	21	27	8	15,33 €
48AT5-16/ECO	48	76,42	75,15	-	50	21	27	8	17,24 €
60AT5-16/ECO	60	95,52	94,25	-	65	21	27	8	25,76 €

Dimensions in mm

## Our other products



PTKFss

Fixable foot for the food industry, Stainless steel - 3-A standard



PSG15S

Spur gear - precision range, Stainless steel 316



PM2

Worm and wheel set, Hardened steel



SDG\_SS

Universal adjustable guide support bracket, Stainless steel



BLHM20

Right angled gearbox, double output shafts, up to 1.77 Nm



LVT

Miniature motorised actuator 2A, 2 amperes




RTN

BoWex® curved tooth gear coupling, Nylon



BLH60

 Right angled gearbox, from 19 to 70 Nm



PRF\_PSA

Shaft support for aluminium profile, Shaft support



TRMSS

Spur round rack, Stainless steel - module 1-5



BAGSS

Stainless steel Clamping collar, Stainless steel



PDM\_PDV

Detectable plastic palm grip, blue thermoplastic

## Complementary products



GTC

Belt tensioner, For standard applications



AT5courroie

AT type timing belt, AT5 Steel cored polyurethane



AT5-BAR

AT type tooth bar stock, AT5



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane