

Aluminium

Pitch AT5



For 16mm belts



- For use with AT5 belts
- Pitch 5mm
- Material: Aluminium

Accessories

- AT5 belts
- GTC tension rollers

Info

- *Pilot bore size given as a indication, may vary between batches.
- Will require re-machining by customer
- **We are unable to modify this product**

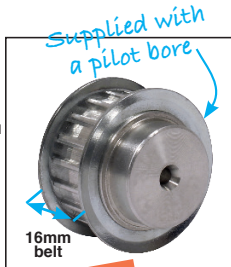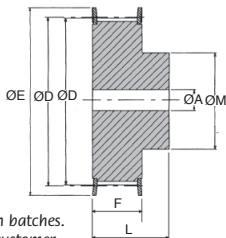

Economy range

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	Ø PDC	ØD external	ØE flange	ØM	F	L	Pilot bore not guaranteed	
								ØA*	Price each 1 to 5
12AT5-16/ECO	12	19,10	17,85	23	11	21	27	-	3,38 €
14AT5-16/ECO	14	22,29	21,05	25	13	21	27	-	3,70 €
15AT5-16/ECO	15	23,88	22,65	28	16	21	27	6	4,06 €
16AT5-16/ECO	16	25,47	24,20	32	18	21	27	6	4,41 €
18AT5-16/ECO	18	28,65	27,40	32	20	21	27	6	4,74 €
19AT5-16/ECO	19	30,25	29,00	36	22	21	27	6	5,24 €
20AT5-16/ECO	20	31,83	30,60	36	23	21	27	6	5,48 €
22AT5-16/ECO	22	35,02	33,85	38	24	21	27	6	6,31 €
24AT5-16/ECO	24	38,21	37,00	42	26	21	27	6	6,80 €
25AT5-16/ECO	25	39,80	38,60	44	26	21	27	6	7,21 €
26AT5-16/ECO	26	41,39	40,20	44	26	21	27	6	7,85 €
27AT5-16/ECO	27	42,98	41,80	48	30	21	27	8	7,95 €
28AT5-16/ECO	28	44,58	43,35	48	32	21	27	8	8,71 €
30AT5-16/ECO	30	47,76	46,55	51	34	21	27	8	9,25 €
32AT5-16/ECO	32	50,94	49,70	54	38	21	27	8	10,43 €
36AT5-16/ECO	36	57,31	56,05	64	38	21	27	8	12,29 €
40AT5-16/ECO	40	63,66	62,45	66,5	40	21	27	8	13,83 €
42AT5-16/ECO	42	66,86	65,60	70	40	21	27	8	14,87 €
44AT5-16/ECO	44	70,05	68,80	-	45	21	27	8	15,33 €
48AT5-16/ECO	48	76,42	75,15	-	50	21	27	8	17,24 €
60AT5-16/ECO	60	95,52	94,25	-	65	21	27	8	25,76 €

Dimensions in mm

Our other products



DOMI80

Accessories, Clamping lever



VELM4

Screw-on base for hook-and-loop strip, Polyamide



HFL

One way needle bearing, Needle bearing



GB-RA

Brass spur gear, Brass CuZn39Pb3



PSG3

Spur gear - precision range, Pre-hardened Steel 35NCD6



P40

Worm and wheel gear reducer, up to 18 Nm



PRF_PL_4590

Joining plate for aluminium profile, Joint plate - 45x90 mm



BLHM40

Right angled gearbox, double output shafts, up to 10.3 Nm



CHM30-MOT

Asynchronous AC motorgearboxes 0.09



MEP

Revolving handle for handwheel, Fixed



RTE

Rotex®, jaw coupling, cast iron



PGT

Sliding profile, Sliding panel support

Complementary products



GTC

Belt tensioner, For standard applications



AT5courroie

AT type timing belt, AT5 Steel cored polyurethane



AT5-BAR

AT type tooth bar stock, AT5



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane