

AT-type timing pulley



Pitch AT5

Aluminium



For 25mm belts



- For use with AT5 belts
- Pitch 5mm
- Material:
Aluminium

Accessories

- AT5 belts
- GTC tension rollers

Info

- *Pilot bore given as indication, may vary between batches.
- Will require re-machining by customer
- We are unable to modify this product

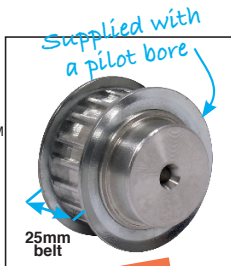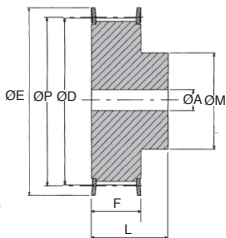

Economy range

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	ØP PDC	ØD external	ØE flange	ØM	F	L	Pilot bore not guaranteed	
								ØA*	Price each 1 to 5
12AT5-25/ECO	12	19,10	17,85	23	11	30	36	-	3,94 €
14AT5-25/ECO	14	22,29	21,05	25	13	30	36	-	4,36 €
15AT5-25/ECO	15	23,88	22,65	28	16	30	36	6	4,74 €
16AT5-25/ECO	16	25,47	24,20	32	18	30	36	6	5,24 €
18AT5-25/ECO	18	28,65	27,40	32	20	30	36	6	5,61 €
19AT5-25/ECO	19	30,25	29,00	36	22	30	36	6	6,23 €
20AT5-25/ECO	20	31,83	30,60	36	23	30	36	6	6,66 €
22AT5-25/ECO	22	35,02	33,85	38	24	30	36	6	7,63 €
24AT5-25/ECO	24	38,21	37,00	42	26	30	36	6	8,45 €
25AT5-25/ECO	25	39,80	38,60	44	26	30	36	6	9,03 €
26AT5-25/ECO	26	41,39	40,20	44	26	30	36	6	9,73 €
27AT5-25/ECO	27	42,98	41,80	48	30	30	36	8	9,91 €
28AT5-25/ECO	28	44,58	43,35	48	32	30	36	8	10,75 €
30AT5-25/ECO	30	47,76	46,55	51	34	36	36	8	11,54 €
32AT5-25/ECO	32	50,94	49,70	54	38	30	36	8	12,95 €
36AT5-25/ECO	36	57,31	56,05	64	38	30	36	8	15,20 €
40AT5-25/ECO	40	63,66	62,45	66,5	40	30	36	8	17,15 €
42AT5-25/ECO	42	66,86	65,60	70	40	30	36	8	18,61 €
44AT5-25/ECO	44	70,05	68,80	-	45	30	36	8	19,54 €
48AT5-25/ECO	48	76,42	75,15	-	50	30	36	8	22,06 €
60AT5-25/ECO	60	95,52	94,25	-	65	30	36	8	32,94 €

Dimensions in mm

Our other products



SC2

2 part rigid shaft clamp, Clamping jaw



BSP

Compact precision slide, from 156 N to 980 N



 
D-PAR_SS

Stainless steel progressive stop, stainless steel



CHA_GC_95S

Stainless steel garnet hinge, To be welded



M1

Worm and wheel set, Machined plastic (delrin)



STL

Guidance brush - Rail, Rail



R205

Die spring ISO10243, Heavy



YG1

HEAVY DUTY spur gear, Steel 35NCD16



NT121

Spur gear coaxial gearbox, from 20 to 68 Nm - In-line



BPH

Ball transfer unit plain fit, High



KITdog

24V DC motorisation kit, Worm and wheel



M0

Worm and wheel set, Machined plastic (delrin)

Complementary products



GTC

Belt tensioner, For standard applications



AT5courroie

AT type timing belt, AT5 Steel cored polyurethane



AT5-BAR

AT type tooth bar stock, AT5



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane